

## SPECIFICATIONS

### Mechanical

**Contact Retention Force:** N/A

**Durability :** 25 Cycles

### Electrical

**Voltage Rating:** N/A

**Current Rating:** N/A

**Contact Resistance:** N/A

**Dielectric Withstanding Voltage:** N/A

**Insulation Resistance:** N/A

### Physical

**Cap:** Thermoplastic, UL 94V-0 rated in Ivory Color

**Metal Spring:** Stainless steel

**Plating:** See "ORDERING INFORMATION"

**Operating Temperature:** -40 °C to +85 °C

## MINI PCI Express Socket


**AS Series**

**5.6mm Height SMT Type**

**0.80mm [.031"] Pitch**

**52 Pos. CLIP**

**P/N: AS0B226-S56K-7H**

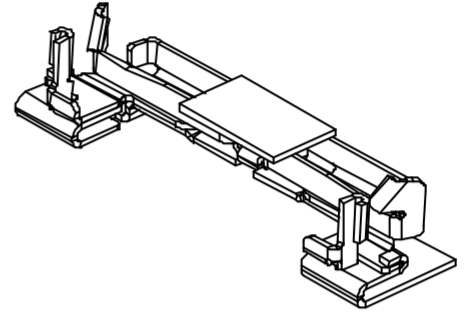

## DRAWING

