

深圳市亚特联科技有限公司

电机型号(Model):

YJSDJ-12FN20-244-0647

样品单号(Sample Code):

CG-181113258

日期(Date):

2018-11-22

额定电压 V
Rated Voltage

6

使用环境温度范围 °C
Operating Condition
Temperature Range

-10~+60

空载转速 rpm
Noload speed

46±10%

空载电流 mA
Free-load Current

≤36

负载转矩 Kg·cm
Rated Torque

0.3

负载转速 rpm
Onload speed

38±10%

负载电流 mA
Roted Current

≤84

堵转电流 mA
Stall Current

280(Ref)

堵转力矩 Kg·cm
Stall Torque

≥1.2

旋向 CW/CCW
Direction



CCW

噪音 dBA
Noise (L=300mm)


55 (Max)

轴向间隙 mm
Axial gap

0.02~0.3

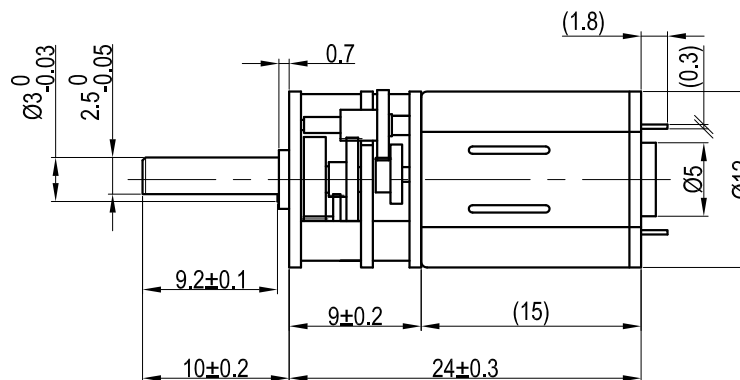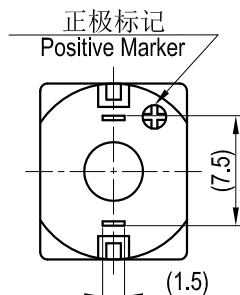

旋转方向
DIRECTION OF ROTATION

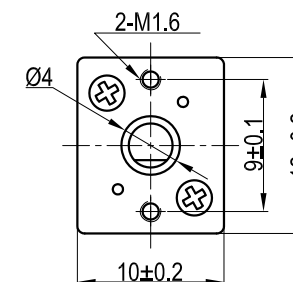

外形图
outside drawing

客户确认
Confirmation Approved

制订:
Formulate

洪生

Unit mm Size A4

审核:
Audit

version A0 Scale 1:1

批准:
Approved

Phase marker S

Page