

SPECIFICATIONS

USB Connector

Mechanical


Mating Force: 3.50Kg (7.71Lb) max.
Unmating Force: 1.00Kg (2.20Lb) min.
Durability: 1500 Cycles

Electrical


Current Rating: 1.5A
Contact Resistance: 30m Ω max.
Dielectric Withstanding Voltage: 500V AC/1min min.
Insulation Resistance: 1000M Ω min.

Physical

Housing: Thermoplastic, UL 94V-0 rated
Contact and Shell: Copper alloy
Plating: See "ORDERING INFORMATION"
Operating Temperature: -55°C to +85°C

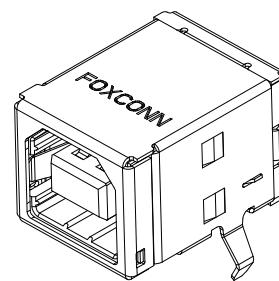

DRAWING

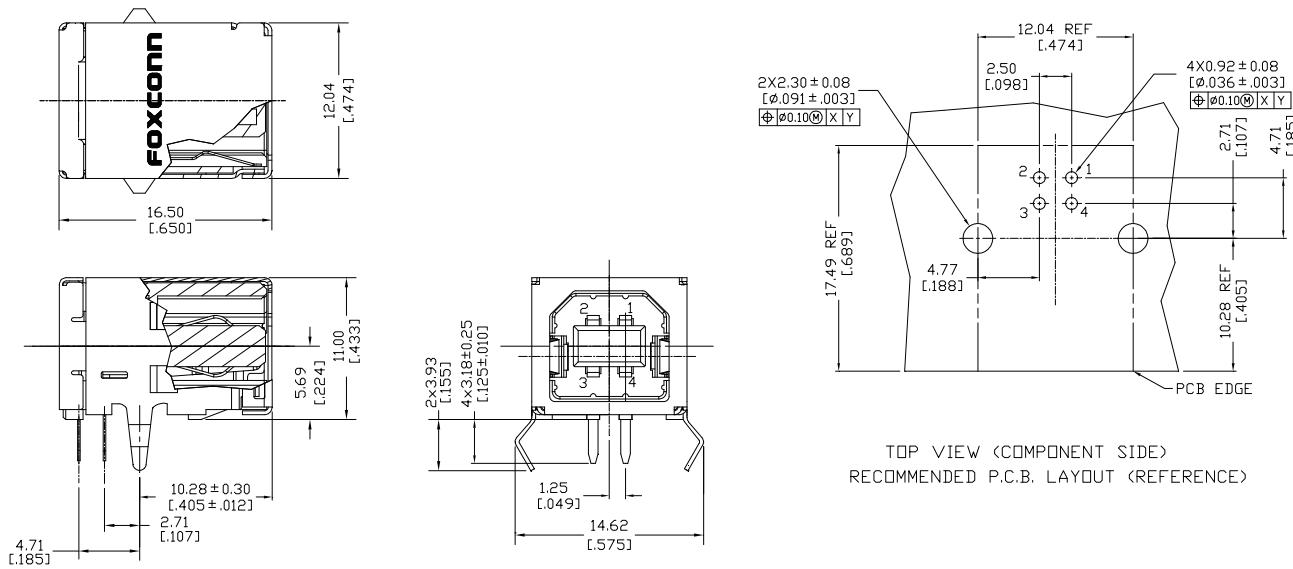

ORDERING INFORMATION

PRODUCT NO. UC 1 1 1 2 * - 1 1 K A - 4 F

UC=USB B TYPE

1=RIGHT ANGLE

1=FEMALE CONTACT

1=4 POS.

EXTENSION CODE

MODIFY CODE

CONTACT AREA PLATING

3=30u" GOLD

C=30u"Pd/Ni+GOLD FLASH

PROFILE HEIGHT

2=5.69 mm