


Model B Stack-Up Banana Plug Patch Cord

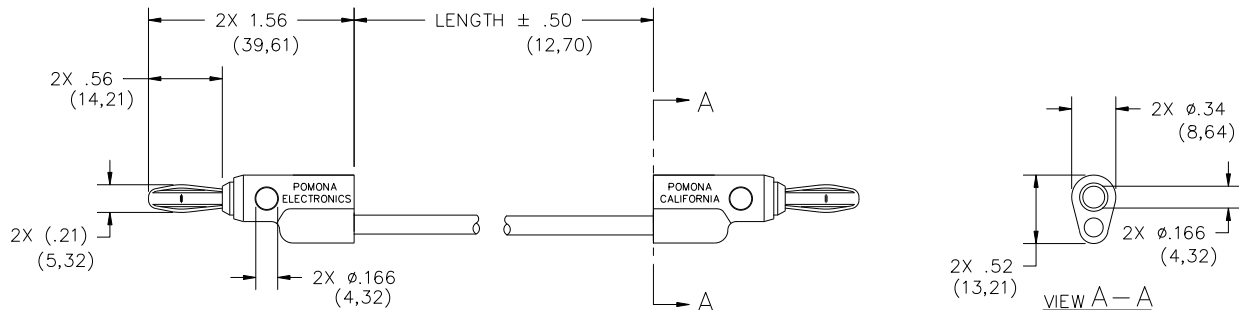

Features

- Mates to Model #1581, 2854 or any standard size banana jack.
- Cross and vertical stacking banana plug.
- Ideal for providing jumpers or chassis boxes.

Materials

Connector: Stacking Banana Plug

Spring – Beryllium Copper per ASTM-B-194, Alloy 172;

Plug Body – Zinc, Die Cast

Finish: Nickel plate

Insulation: Polypropylene molded to the plug body and wire

Color: *Matches color of the wire*

Wire: 18 AWG, stranding 65 x 36 t.c., PVC insulated, 3.66mm (0.144") O.D.

Color: *See Order Information*

Marking: "POMONA B-XX-"



Ratings (Entire Assembly)

Operating Temperature: +55°C (+131°F) Max

Operating Voltage: For *CE compliance* and for personal safety, do not hold in hand when voltages exceed 30 Vrms/60 Vdc.

Maximum voltage for *hands free use* in controlled testing environments: 5000 WVDC

Do not use on circuits where transient stresses can exceed the rated voltage.

Current: 15 Amperes Cont..

Ordering Information

Model: B-XX-*

XX = Cable Length; Standard Lengths: 4" (102), 8" (203), 12" (305), 18" (457), 24" (610), 36" (914), 48" (1219), 60" (1524) & 72" (1829). *Additional lengths can be quoted upon request.*

* = Color, -0 Black, -1 Brown, -2 Red, -3 Orange, -4 Yellow, -5 Green, -6 Blue, -7 Violet, -8 Gray, -9 White

Ordering Example: B-72-2 Indicates 72" in length, Color is Red.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm$.02" (.51 mm), .xxx = $\pm$.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.