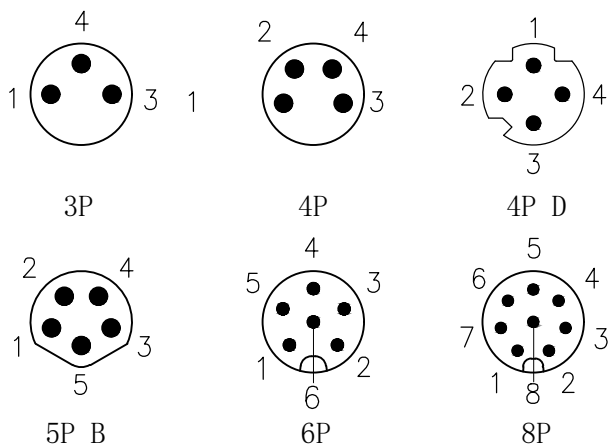
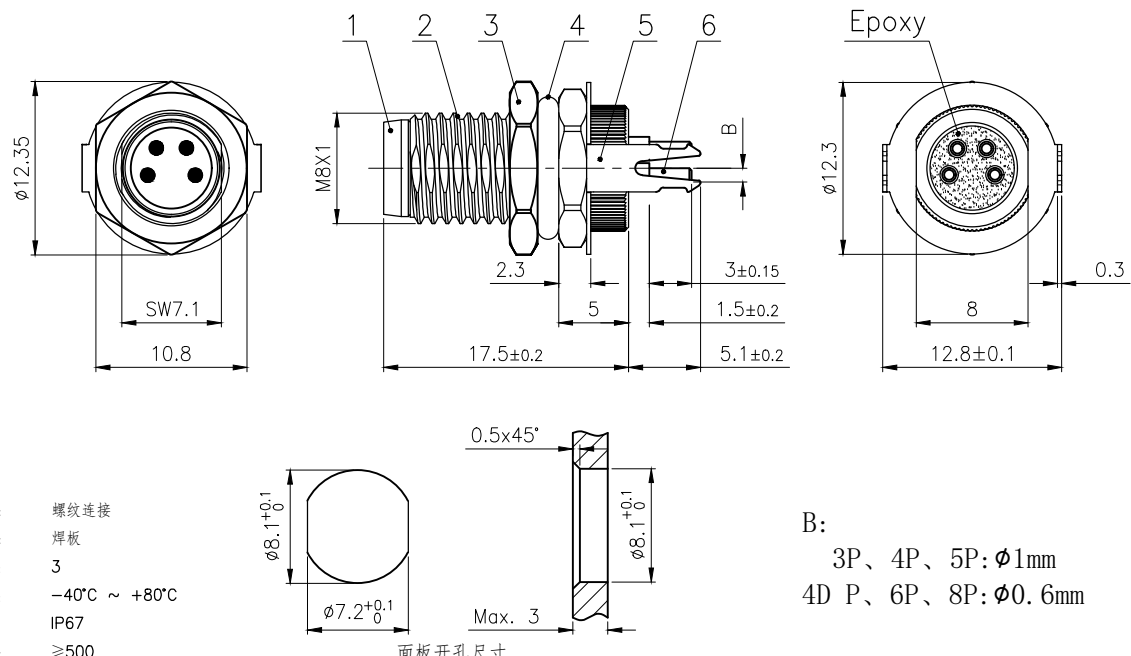
 


1		2		3		4		5		6	
芯位排布				芯数		3	4	4D	5	6	8
				额定电流/电压		3A/60V	3A/60V	4A/60V	3A/30V	1.5A/30V	1.5A/30V
				额定脉冲电压		1500V	1500V	1500V	800V	800V	800V
				绝缘阻抗 (MΩ)		≥100	≥100	≥100	≥100	≥100	≥100
				接触阻抗 (MΩ)		≤5	≤5	≤5	≤5	≤5	≤5
P.C.B开孔尺寸											
技术参数				连接方式: 螺钉连接 接线方式: 焊板 污染等级: 3 温度范围: -40℃ ~ +80℃ 防护等级: IP67 插拔周期: ≥500							
面板开孔尺寸				B: 3P、4P、5P: φ1mm 4D P、6P、8P: φ0.6mm							
6	插板式公针直针镀金	pc	3~8	GENERAL TOLERANCE (UNLESS SPECIFIED)		绘图 DWN		W. M 2024. 8. 26			
5	M8螺纹式,直式座子屏蔽卡扣外壳铜外壳	pc	1	≤10 ±0.1		确认 CHK					
4	丁腈橡胶 φ9*φ6*1.5 黑色	pc	1	<10~≤20 ±0.2							
3	六角螺母黄铜 M8*1螺纹 (M8板后螺母) 亮镍	pc	1	<20~≤50 ±0.5		核准 APVD		品名 TITLE		M8板后安装针型金属插座 插板式 锁板牙M8*1 直式屏蔽	
2	M8螺纹式板后,公座弯式铜外壳 锁板牙M8*1	pc	1	Angle ±1°		单位 UNIT		MM	版本 REV	A	品号 PART NO
1	M8 针型胶芯长体 黑色	pc	1	 视角 THIRD ANGLE		尺寸 SIZE		A4	页码 SHEET	1 OF 1	型号 DRAWING NO
No.	Specification	Unit	Q'ty								