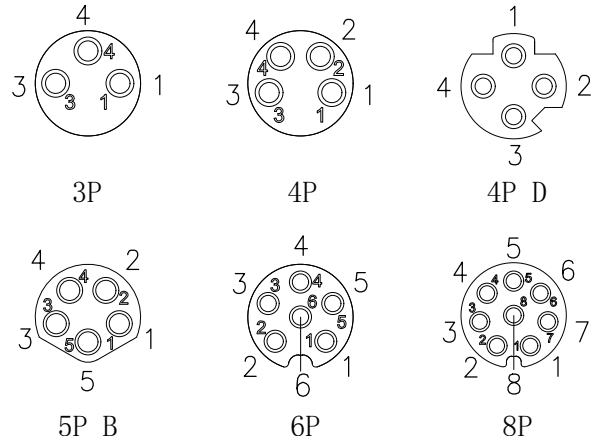
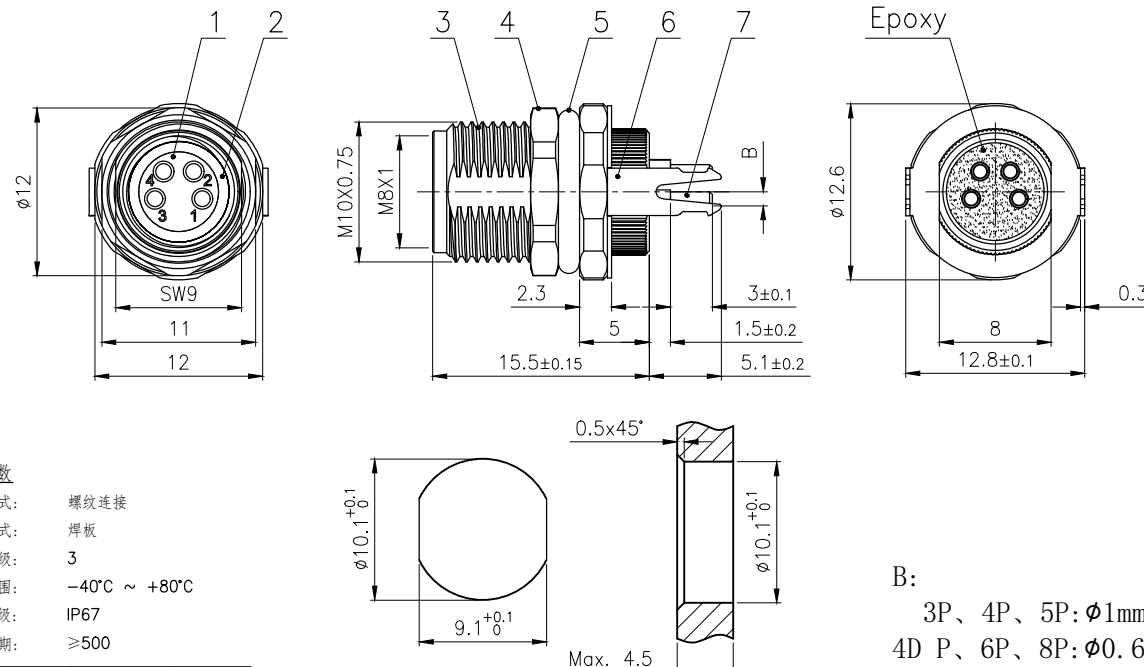


1		2		3		4		5		6	
芯位排布				芯数		3	4	4D	5	6	8
				额定电流/电压		3A/60V	3A/60V	4A/60V	3A/30V	1.5A/30V	1.5A/30V
				额定脉冲电压		1500V	1500V	1500V	800V	800V	800V
				绝缘阻抗 (MΩ)		≥100	≥100	≥100	≥100	≥100	≥100
				接触阻抗 (MΩ)		≤ 5	≤ 5	≤ 5	≤ 5	≤ 5	≤ 5
P.C.B开孔尺寸											
3P				技术参数							
4P				连接方式: 螺纹连接							
4D P				接线方式: 焊板							
5P				污染等级: 3							
6P				温度范围: -40℃ ~ +80℃							
8P				防护等级: IP67							
				插拔周期: ≥500							
7				插板式母针直针镀金		pc	3~8				
6				M8螺纹式,直式座子屏蔽卡扣外壳铜外壳		pc	1				
5				丁腈橡胶 φ10*φ7*1.5黑色		pc	1				
4				六角螺母黄铜 M10*0.75螺纹(M8弯式板后母座螺母) 亮镍		pc	1				
3				M8螺纹式板后,母座弯式铜外壳 锁板牙M10*0.75		pc	1				
2				丁腈橡胶 φ7*φ5.4*0.8黑色		pc	1				
1				M8 孔型胶芯长体带倒角 黑色		pc	1				
No.				Specification		Unit	Q'ty				
1		2		3		4		5		6	