


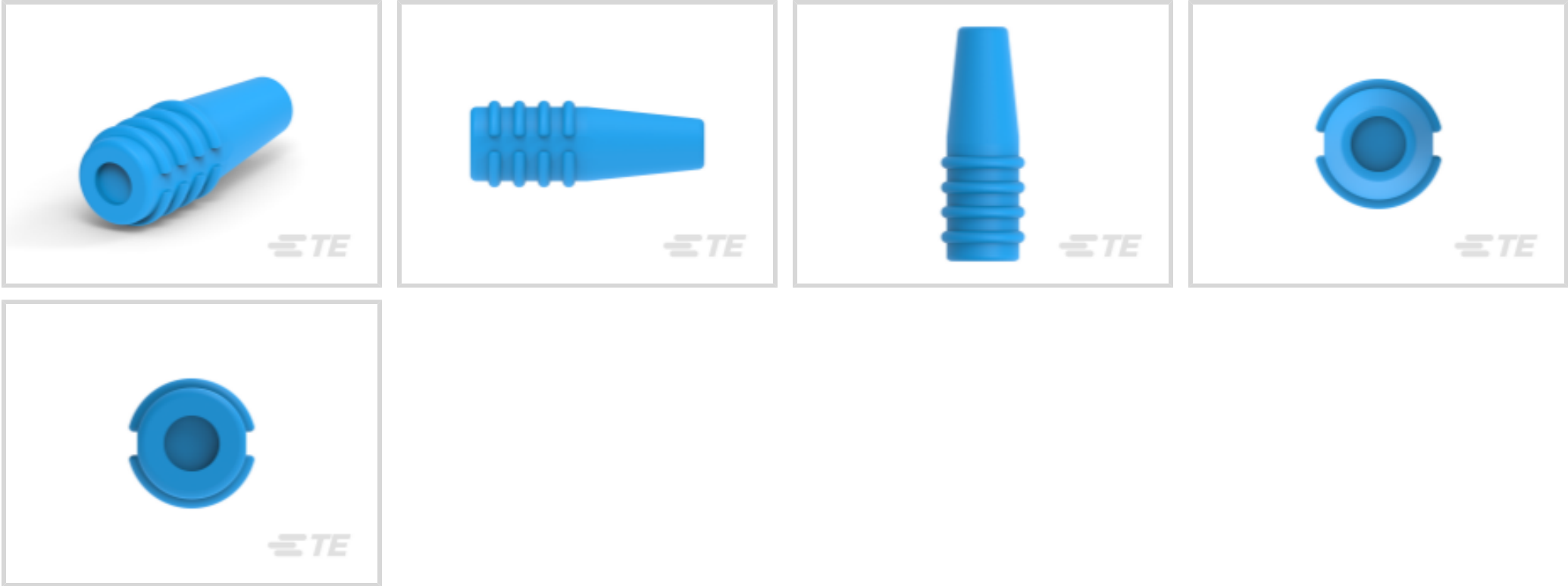

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUN 2020 (209) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought

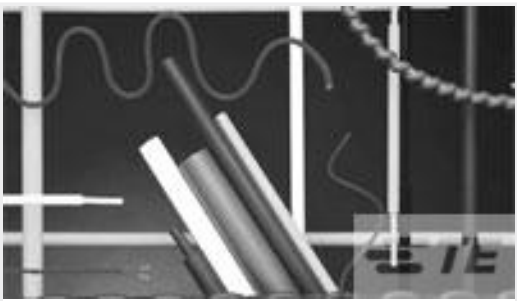

TE Part #5069742011
CGPT-12.7/6.4-X-STK



TE Part #4169106001
DSPL-NR3-X-65MM




TE Part #6-1676914-3
YR1 0.1% 56R2




TE Part #4-1879314-5
DPL12S 24P 24DET 25K RD/GRN



TE Part #3-1879208-9
CPF 0402 390R 0.1% 25PPM 1K RL

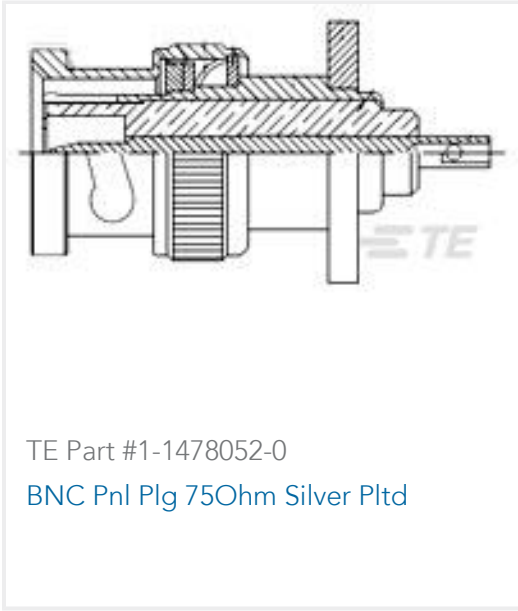

TE Part #1-1478052-0
BNC Pnl Plg 75Ohm Silver Pltd

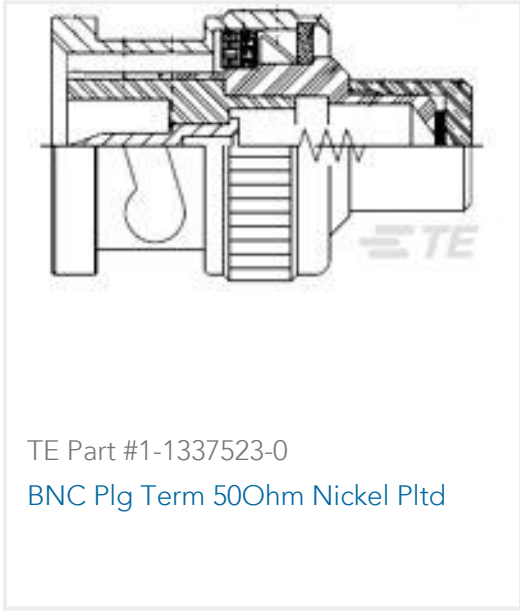

TE Part #1-1337523-0
BNC Plg Term 50Ohm Nickel Pltd



TE Part #2-1879027-2
YR1 0.1% 787K



TE Part #6-1879026-5
YR1 0.1% 35R7



TE Part #5-1634511-1
BNC Str Jk Hex 50Ohm Nickel Pltd
RG174A/

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-1478996-2_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-1478996-2_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-1478996-2_A.3d_stp.zip

English

Customer View Model

ENG_CVM_1-1478996-2_A.3d_igs.zip

English

Customer View Model

ENG_CVM_1-1478996-2_A.3d_stp.zip

English



Customer View Model

[ENG_CVM_1-1478996-2_A.2d_dxf.zip](#)

English

[3D PDF](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[1307191 RF Coax Products Catalog](#)

English