


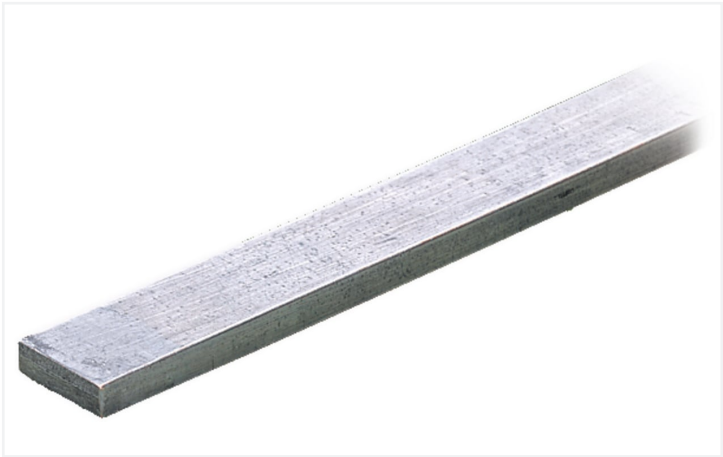

Color: white

Electrical data	
Rated current	140 A

Physical data	
Length	1000 mm

Material data	
Color	white
Fire load	0 MJ
Weight	266 g

Commercial data	
eCl@ss 10.0	27-14-11-39
eCl@ss 9.0	27-14-11-39
ETIM 9.0	EC000485
ETIM 8.0	EC000485
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454229443
Customs tariff number	7407100000

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption



Downloads

Environmental Product Compliance

Compliance Search			
Environmental Product Compliance 210-133			

Documentation

Bid Text			
210-133	19.02.2019	xml 2.54 KB	
210-133	23.11.2018	docx 13.39 KB	

CAD/CAE-Data

CAD data			
2D/3D Models 210-133			

CAE data	
EPLAN Data Portal 210-133	
WSCAD Universe 210-133	
ZUKEN Portal 210-133	

1 Compatible Products

1.1 Optional Accessories

1.1.1 Cover

1.1.1.1 Cover



Item No.: 777-303 N-busbar cover; 1000 mm long; transparent
--

1.1.2 N-busbar

1.1.2.1 Busbar terminal block



Item No.: 210-281 Connector; blue
--



Item No.: 209-105 Connector; silver-colored
--

1.1.3 Shield termination

1.1.3.1 Shield clamping saddles



Item No.: 790-108
Shield clamping saddle; 11 mm wide; diameter of compatible conductor; 3 ... 8 mm



Item No.: 790-208
Shield clamping saddle; 12.4 mm wide; 3 ... 8 mm



Item No.: 790-116
Shield clamping saddle; 19 mm wide; diameter of compatible conductor; 7 ... 16 mm



Item No.: 790-216
Shield clamping saddle; 21.8 mm wide; 6 ... 16 mm



Item No.: 790-124
Shield clamping saddle; 27 mm wide; diameter of compatible conductor; 6 ... 24 mm



Item No.: 790-220
Shield clamping saddle; 30 mm wide; 6 ... 20 mm



Item No.: 790-140
Shield clamping saddle; diameter of compatible conductor

1.1.3.2 Shield termination



Item No.: 791-107
Shield clamp; diameter of compatible conductor; 1.5 mm to 6.5 mm; H max. 40 mm; 10 mm wide



Item No.: 791-117
Shield clamp; diameter of compatible conductor; 10 mm to 17 mm; H max. 63 mm; 23 mm wide



Item No.: 791-124
Shield clamp; diameter of compatible conductor; 16 mm to 24 mm; H max. 78 mm; 30 mm wide



Item No.: 791-111
Shield clamp; diameter of compatible conductor; 5 mm to 11 mm; H max. 47 mm; 17 mm wide



Item No.: 790-398
T-connector; for busbars Cu 10 mm x 3 mm; silver-colored

1.1.4 Terminal blocks

1.1.4.1 Common potential terminal block



Item No.: 812-114
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; 16,00 mm²; blue



Item No.: 812-112
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; 16,00 mm²; dark gray



Item No.: 812-111
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; 16,00 mm²; light gray



Item No.: 812-113
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; CAGE CLAMP®; 16,00 mm²; red



Item No.: 812-104
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; blue



Item No.: 812-102
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; dark gray



Item No.: 812-101
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; light gray



Item No.: 812-103
Busbar terminal block; for (10 x 3) mm busbars; without push-buttons; Push-in CAGE CLAMP®; 4,00 mm²; red



Item No.: 812-110
Ground busbar terminal block; for (10 x 3) mm busbars; CAGE CLAMP®; 16,00 mm²; green-yellow



Item No.: 812-100
Ground busbar terminal block; for (10 x 3) mm busbars; Push-in CAGE CLAMP®; 4,00 mm²; green-yellow