


Data Sheet | Item Number: 216-222

Ferrule; Sleeve for 0.75 mm² / 18 AWG; insulated; electro-tin plated; gray

<https://www.wago.com/216-222>



Color: ■ gray

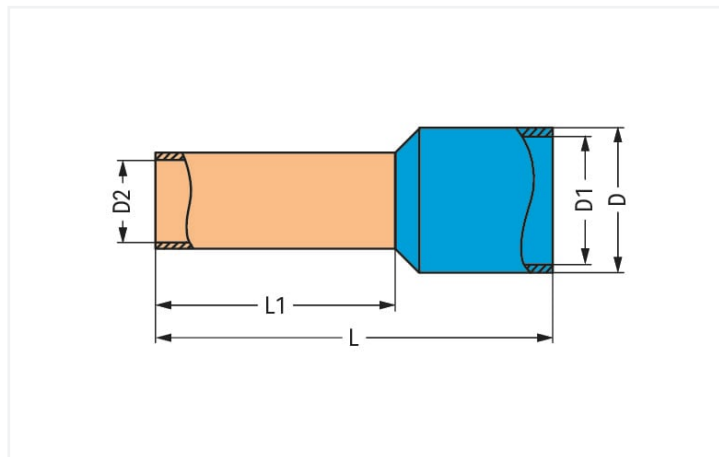

Dimensions in mm

Connection data

Cross-section metric	0.75 mm ²
Strip length	8 ... 9 mm / 0.31 ... 0.35 inches
Cross-section AWG	18 AWG

Physical data

Wall thickness plastic collar	0.25 mm
Total length	12 mm
Wall thickness crimp sleeve	0.15 mm
Crimp length (length of sleeve)	6 mm
Inner Diameter plastic collar	2.8 mm
Diameter crimp sleeve inside	1.2 mm

Mechanical data

Plastic collar	Standard collar
----------------	-----------------

Material data

Color	gray
Fire load	0.001 MJ
Weight	0.1 g

Commercial data

Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-02-01
eCl@ss 9.0	27-40-02-01
ETIM 9.0	EC000005
ETIM 8.0	EC000005
PU (SPU)	1000 pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332277440
Customs tariff number	85369010000



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 216-222

↓

Documentation				
Bid Text				
216-222	19.02.2019	xml	2.80 KB	↓
216-222	11.09.2017	doc	23.50 KB	↓


CAD/CAE-Data

CAD data

2D/3D Models 216-222

↓

Installation Notes

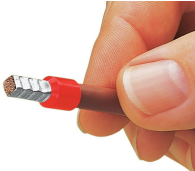

A perfect gas-tight crimp – both electrical-ly and mechanically reliable