

Color: ■ orange

Similar to illustration

Dimensions in mm

Connection data	
Cross-section metric	0.5 mm²
Strip length	9 ... 10 mm / 0.35 ... 0.39 inches
Cross-section AWG	20 AWG

Physical data	
Wall thickness plastic collar	0.25 mm
Total length	14 mm
Wall thickness crimp sleeve	0.15 mm
Crimp length (length of sleeve)	8 mm
Inner Diameter plastic collar	2.6 mm
Diameter crimp sleeve inside	1 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	orange
Fire load	0 MJ
Weight	0.1 g

Commercial data	
PU (SPU)	5000 pcs
Packaging type	Foil
GTIN	4055143968461



Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads


Environmental Product Compliance

Compliance Search

Environmental Product Compliance  
216-304/001-000

↓

Installation Notes

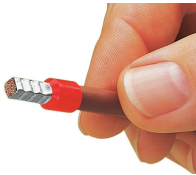

A perfect gas-tight crimp – both electrical-ly and mechanically reliable