


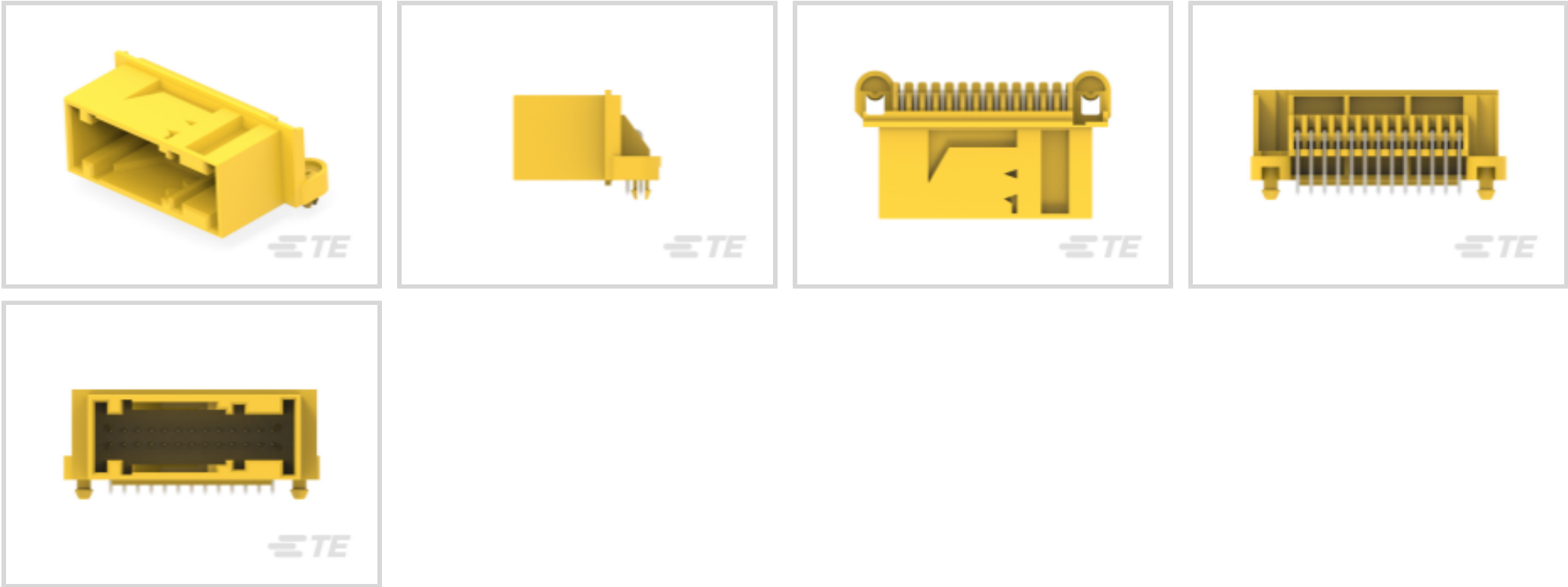

[All Signal Header \(246\)](#)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # 185791-7
0.63 SQR PIN CONTACT 25.6

TE Part # CAT-M8793-CH8172
MQS, CONNECTOR HOUSING

TE Part # 185791-3
0.63 SQR PIN CONTACT 20.5

TE Part # 185879-2
26W MQS COVER ASSY BLUE

TE Part # 185879-3
26W MQS COVER ASSY RED

Customers Also Bought

TE Part #185534-2
26pos MQS .63 header 90deg

TE Part #5103308-1
A/L LOW PRO HDR 10P VERT BLACK

TE Part #5103310-1
A/L LOW PRO HDR 10P RA BLACK

TE Part #928814-1
250 FASTON TAB TPBR

TE Part #284617-1
154pos hybrid MQS .63 header 90deg sld.

TE Part #2176331-9
CRGP 2512 47R 1%

TE Part #280371-2
4P AMPMODU II SHRD HDR, ST, 0.38 AU

TE Part #293266-2
32+8 position mqs header ass'y

TE Part #1393280-6
V23086C1001A403

TE Part #1-963224-1
42P MESSERLEIST MIX



Documents

Product Drawings

26pos MQS .63 header 90deg

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_185534-1_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_185534-1_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_185534-1_O.3d_stp.zip

English

Customer View Model

ENG_CVM_185534-1_C.3d_igs.zip

English

Customer View Model

ENG_CVM_185534-1_C.3d_stp.zip

English

Customer View Model

ENG_CVM_185534-1_C.2d_dxf.zip

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English