



All MULTILOCK, CONNECTOR HOUSING (146)

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>




Compatible Parts



TE Part # CAT-LMPH9507
Low & Medium Power Header

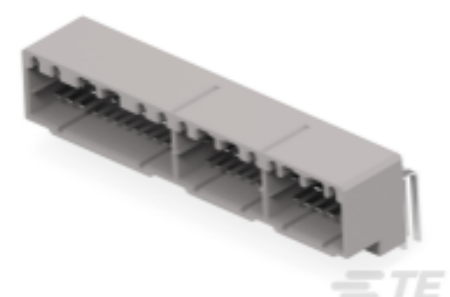


TE Part # 175448-6
HYBRID I/O CAP ASSY 54P

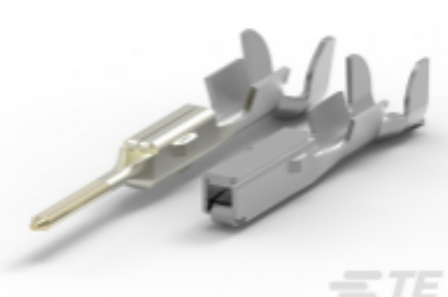

TE Part # CAT-M9194-T273
MULTILOCK, RECEPTACLE AND TAB


Customers Also Bought

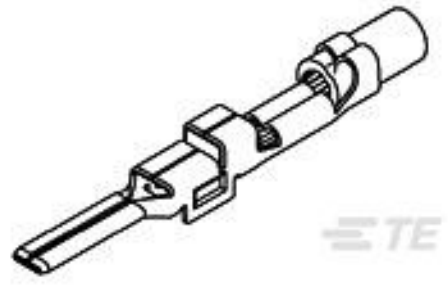

TE Part #368086-1
090III NON SLD TAB(SQ 2.0)




TE Part #1743059-2
MT-II/JPT SLD 36P PLUG ASSY

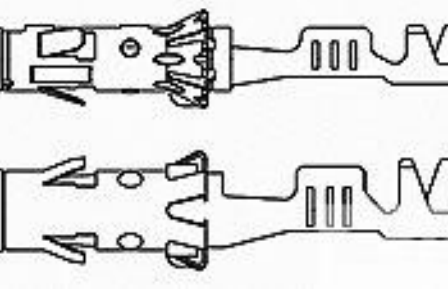

TE Part #962954-2
4MM BUCHS-KONTAKT



TE Part #CH03466001
QSZH-125-NR1-40MM

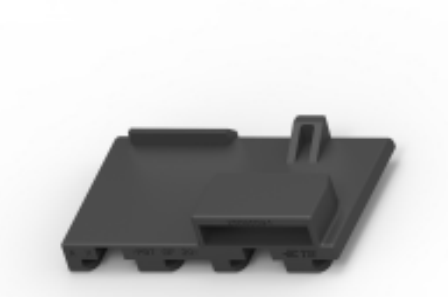


TE Part #2066559-1
REAR LOCK, ENGINE COMPT FRB



TE Part #CAT-AM705-T273
AMP MCP, RECEPTACLE AND TAB



TE Part #2098557-1
2POS, MCON 1.2 CB REC 2p TL SEALED

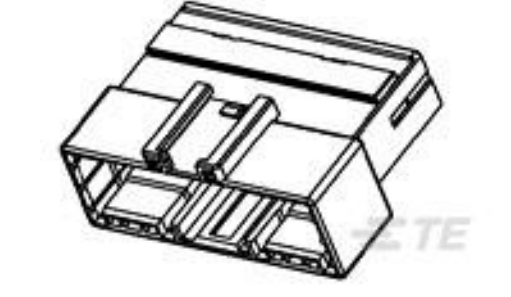

TE Part #936133-1
090III 26P CAP ASSY



TE Part #2288186-1
RELAY BOX ASSY HARD WIRED
MINIRLY 6.3MCP

Documents

Product Drawings

070 12P PLUG HSG

CAD Files

3D PDF

3D

Customer View Model



[ENG_CVM_CVM_2005155-1_A_c-2005155-1-a.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2005155-1_A_c-2005155-1-a.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2005155-1_A_c-2005155-1-a.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[MULTILOCK Connector System](#)

English

Product Specifications

[Product Specification](#)

English