




Color: ■ red

Similar to illustration

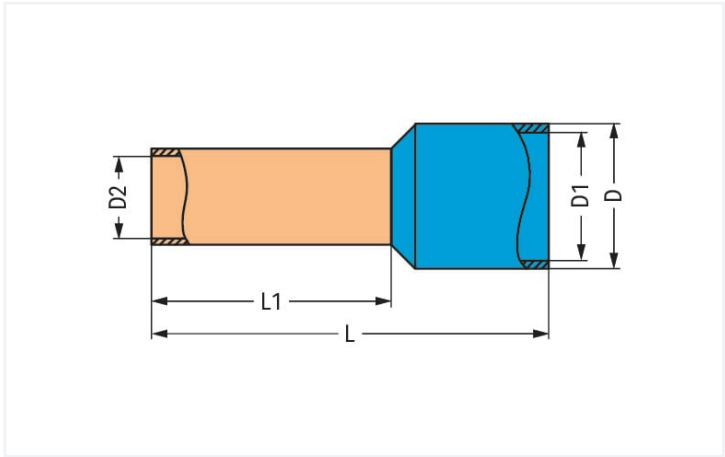

Dimensions in mm

Connection data	
Cross-section metric	1 mm²
Strip length	10 ... 11 mm / 0.39 ... 0.43 inches
Cross-section AWG	18 AWG

Physical data	
Wall thickness plastic collar	0.25 mm
Total length	14 mm
Wall thickness crimp sleeve	0.15 mm
Crimp length (length of sleeve)	8 mm
Inner Diameter plastic collar	3 mm
Diameter crimp sleeve inside	1.4 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	red
Fire load	0.001 MJ
Weight	0.1 g

Commercial data	
Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-02-01
eCl@ss 9.0	27-40-02-01
ETIM 9.0	EC000005
ETIM 8.0	EC000005
PU (SPU)	1000 (100) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332277471
Customs tariff number	85369010000



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 216-203

↓

Documentation				
Bid Text				
216-203	19.02.2019	xml	2.80 KB	↓
216-203	11.09.2017	doc	24.00 KB	↓

Installation Notes

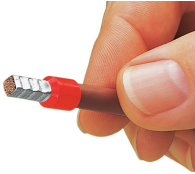

A perfect gas-tight crimp – both electrical-ly and mechanically reliable