


Data Sheet | Item Number: 758-974

Radio antenna; with 2m cable and SMA plug; GSM/ UMTS/ LTE/ Bluetooth®/ WLAN;
698-960, 1710-6000 MHz; 2G/3G/4G/5G

<https://www.wago.com/758-974>

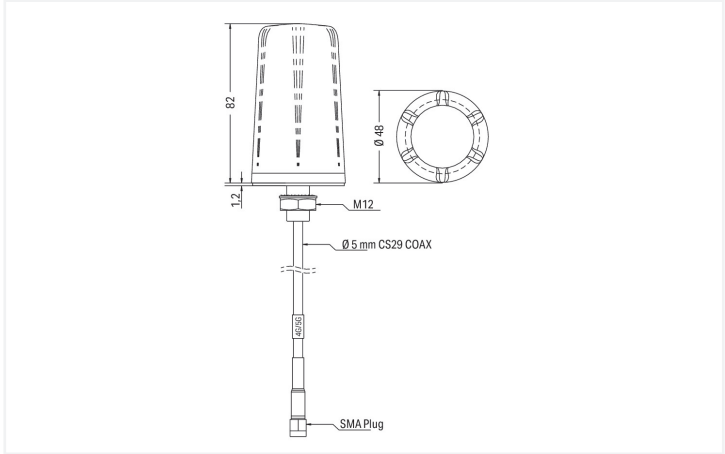

- The antenna must be mounted on a conductive base plate measuring at least 40 x 40 cm.
- The distance of interfering sources to the antenna and antenna line must be at least 30 cm. The free space between the antenna and the next wall must be at least 35 cm.
- The antenna cable must not, under any circumstances, be bent sharply, or the antenna line may be irreversibly damaged.

Technical data	
Radio technology	GSM UMTS LTE Bluetooth® WLAN 5G
Frequency band	617 ... 960 MHz; 1710 ... 6000 MHz
Gain	617 ... 960 MHz: 1dBi; 1710 ... 2700 MHz: 4dBi; 3400 ... 3800 MHz: 8dBi; 4900 ... 6000 MHz: 9dBi

Mechanical data	
Mounting type	Enclosure installation; adhesive strips
Cable type	CS29
Connector	SMA plug
Length of connection cable	2 m

Material data	
Fire load	0 MJ
Weight	185 g

Environmental requirements	
Ambient temperature (operation)	-40 ... +85 °C
Protection type	IP66



Commercial data		
ETIM 9.0		EC001698
ETIM 8.0		EC001698
PU (SPU)		1 pcs
Packaging type		Bag
Country of origin		CN
GTIN		4066966093957
Customs tariff number		85291095900

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 758-974

↓