

Color: ■ orange

Similar to illustration

Dimensions in mm

Connection data	
Cross-section metric	0.5 mm²
Strip length	9 ... 10 mm / 0.35 ... 0.39 inches
Cross-section AWG	20 AWG

Physical data	
Wall thickness plastic collar	0.25 mm
Total length	14 mm
Wall thickness crimp sleeve	0.15 mm
Crimp length (length of sleeve)	8 mm
Inner Diameter plastic collar	2.6 mm
Diameter crimp sleeve inside	1 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	orange
Fire load	0 MJ
Weight	0.1 g

Commercial data	
PU (SPU)	500 pcs
Packaging type	Bag
Country of origin	DE
GTIN	4055143968515
Customs tariff number	85369010000



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads


Environmental Product Compliance

Compliance Search

Environmental Product Compliance 216-304

↓

Installation Notes

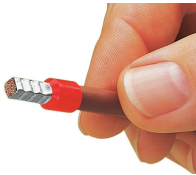

A perfect gas-tight crimp – both electrical-ly and mechanically reliable