


Omnimate Range - Pitch 7.50 mm



Pin headers SL 7.50/90

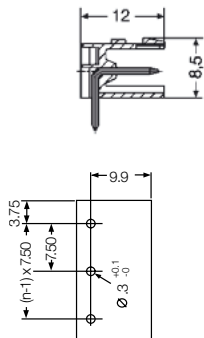


Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	15	10	10

*Overvoltage category III / Pollution severity 3
Additional technical data see page 225

Solder pin length 3.2 mm 4.5 mm

Colour				
Poles	Type	Cat. No.	Cat. No.	Qty.
2	SL 7.50/2/90	1628360000	1628690000	100
3	SL 7.50/3/90	1628370000	1628700000	100
4	SL 7.50/4/90	1628380000	1628710000	100
5	SL 7.50/5/90	1628390000	1628720000	50
6	SL 7.50/6/90	1628400000	1628730000	50
7	SL 7.50/7/90	1628410000	1628740000	50
8	SL 7.50/8/90	1628420000	1628750000	50
9	SL 7.50/9/90	1628430000	1628760000	50
10	SL 7.50/10/90	1628440000	1628770000	50
11	SL 7.50/11/90	1628450000	1628780000	50
12	SL 7.50/12/90	1628460000	1628790000	50

Pin headers SL 7.50/90B

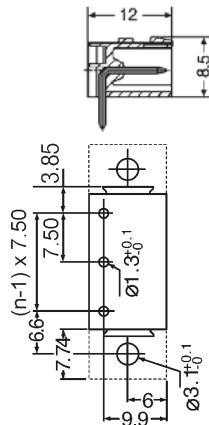

Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	15	10	10

*Overvoltage category III / Pollution severity 3
Additional technical data see page 225

Solder pin length 3.2 mm 4.5 mm

Colour				
Poles	Type	Cat. No.	Cat. No.	Qty.
2	SL 7.50/2/90B	1628470000	1628910000	100
3	SL 7.50/3/90B	1628480000	1628920000	100
4	SL 7.50/4/90B	1628490000	1628930000	100
5	SL 7.50/5/90B	1628500000	1628940000	50
6	SL 7.50/6/90B	1628510000	1628950000	50
7	SL 7.50/7/90B	1628520000	1628960000	50
8	SL 7.50/8/90B	1628530000	1628970000	50
9	SL 7.50/9/90B	1628540000	1628980000	50
10	SL 7.50/10/90B	1628550000	1628990000	50
11	SL 7.50/11/90B	1628560000	1629000000	50
12	SL 7.50/12/90B	1628570000	1629010000	50

Accessories	Page
Fixing	-
Marking	196
Coding	199
Miscellaneous	-

Accessories	Page
Fixing	193
Marking	196
Coding	199
Miscellaneous	-