


1. 产品尺寸图Product Dimension Drawing

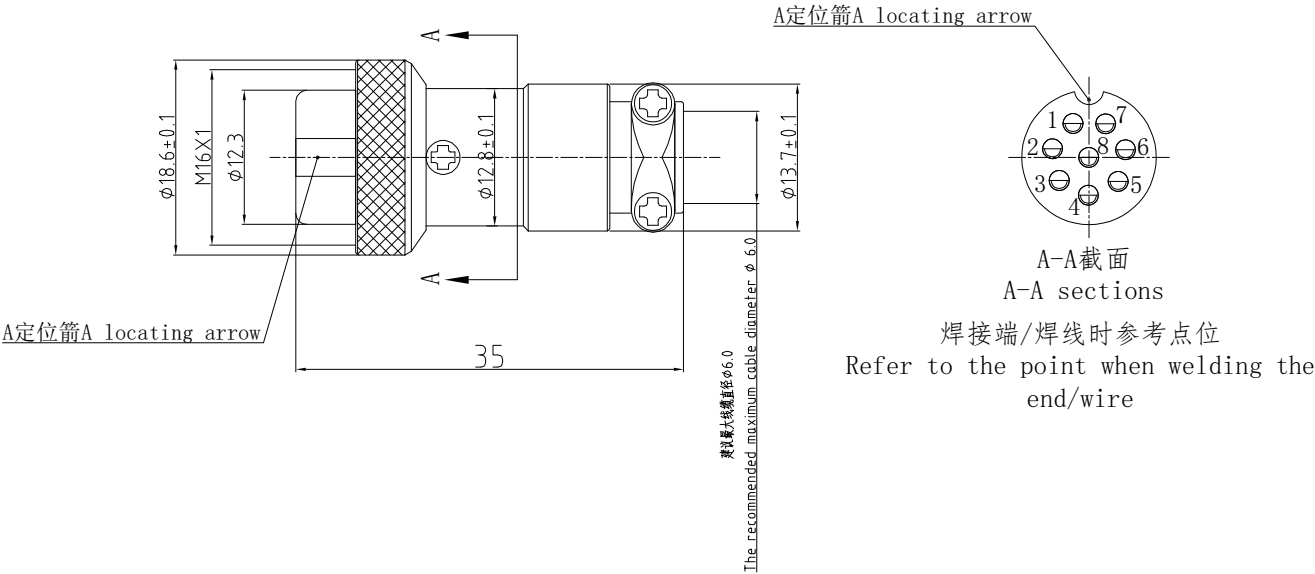

2. 产品电器参数Product electrical parameters

防护等级 (Ingress protection)	IP50
插拔测试 (Plugging and unplugging test)	<500次
产品耐温 (The product is temperature resistant)	-20° C / +85° C
盐雾腐蚀 (Salt Spray Corrosion)	>48 hr
额定电流Current rating	7A
额定电压 (Rated voltage)	125V
工作电压 (AC.V)	200
Operating voltage (AC.V)	
耐电压 (AC.V)	1000
Withstand voltage (AC.V)	
绝缘阻抗 (mΩ) DC500V	1000
Insulation Resistance (mΩ)DC500V	
绝缘电阻 (mΩ) DC1A	3
Insulation Resistance (mΩ)DC1A	

3. 环境及表面处理产品特性Environmental and surface treatment product characteristics

外壳材料 Housing material	锌合金镀镍Zinc alloy nickel plating
绝缘体材料 Insulator material	橡胶黑木Rubber black wood
触体材料 Contact material	黄铜镀银Brass silver-plated

1: 连接器组装生产所有公差通常为0.1mm,2: 插座直接拧入螺纹孔中, 螺纹 +0.05mm
1: All tolerances are usually 0.1mm for connector assembly production, 2: The socket is screwed directly into the threaded hole, the thread is +0.05mm

TONGRUIJOIN

东莞市通瑞电子科技有限公司
TongRuiJoin
Dongguan Tongrui Electronic Technology Co., Ltd
www.CLtfre.com

GX12弯针板接插座GX12
curved pin board socket

单芯图纸Single-core drawings

单位unit:mm 修改revise:A0

视图view:

型号Model
AD. MT. GX16. 308. NYA