





## Series 80 Mighty Mouse Backshells and Accessories

### Jam Nuts 809-094

#### Jam nut for Mighty Mouse connectors

Replace lost or damaged jam nuts with these standard replacement parts. Jam nut fits all Series 80 jam nut receptacles. Use with Glenair tool 600-146

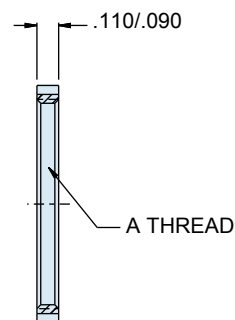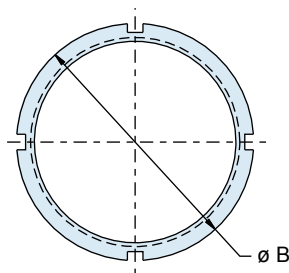

X

| How To Order              |                                                              |    |   |
|---------------------------|--------------------------------------------------------------|----|---|
| Sample Part Number        | 809-094                                                      | -M | 7 |
| Series (See Table I)      | 809-094                                                      |    |   |
| Shell Material and Finish | C = Aluminum / Black Anodize (Non-Conductive) RoHS Compliant |    |   |
|                           | M = Aluminum / Electroless Nickel                            |    |   |
|                           | NF = Aluminum / Cadmium with Olive Drab                      |    |   |
|                           | ZN = Aluminum / Zinc-Nickel with Olive Drab Chromate         |    |   |
|                           | Z1 = Stainless Steel / Passivated                            |    |   |
| Dash No.                  | See Table I                                                  |    |   |

| Dash No. | 800 | 801 | 804       |           | 805  | A Thread Class 2B | B Dia |
|----------|-----|-----|-----------|-----------|------|-------------------|-------|
|          |     |     | -00 style | -07 style |      |                   |       |
| 1        | 5   |     |           |           |      | .3125-28 UN-2B    | 0.43  |
| 2        | 6   | 5   |           |           |      | .3750-28 UN-2B    | 0.50  |
| 3        | 7   | 6   |           |           |      | .4375-28 UNEF-2B  | 0.56  |
| 3-3      |     |     |           | 5         |      | .4375-32 UN-2B    | 0.56  |
| 4        | 8   |     | 5         | 6         |      | .5000-32 UN-2B    | 0.62  |
| 5        |     |     |           |           | 8    | .5625-28 UN-2B    | 0.68  |
| 5-5      | 9   | 7,8 | 6         |           |      | .5625-32 UN-2B    | 0.68  |
| 6        |     | 9   |           | 7,8       |      | .6250-28 UN-2B    | 0.75  |
| 6-6      | 10  |     |           |           |      | .6250-32 UN-2B    | 0.75  |
| 7        |     | 10  | 7,8       | 9         | 9,10 | .6875-28 UN-2B    | 0.81  |
| 8        | 12  | 11  | 9         | 10        | 11   | .7500-28 UN-2B    | 0.87  |
| 9        |     |     | 10        | 11        | 12   | .8125-28 UN-2B    | 0.93  |
| 10       | 14  | 13  | 11        | 12        | 13   | .8750-28 UN-2B    | 1.00  |
| 11       | 15  |     |           |           |      | .9375-28 UN-2B    | 1.06  |
| 12       |     |     | 12        | 14        | 15   | 1.0000-28 UN-2B   | 1.12  |
| 13       |     | 16  | 14        | 15        |      | 1.0625-20 UN-2B   | 1.18  |
| 14       |     | 17  | 15        |           |      | 1.1250-28 UN-2B   | 1.25  |
| 15       |     |     |           |           | 18   | 1.1875-28 UN-2B   | 1.31  |
| 16       |     | 19  |           |           | 19   | 1.2500-28 UN-2B   | 1.37  |
| 18       |     | 21  |           |           | 21   | 1.3750-28 UN-2B   | 1.50  |
| 20       |     |     |           |           | 23   | 1.5000-28 UN-2B   | 1.62  |

Dimensions in Inches (millimeters) are subject to change without notice.