


# WRAPOST RECEPTACLES

FOR 0,38 - 0,64 DIAMETER PINS

## 1702/1703

170X-X-15-XX-30-XX-02-0

Press-fit in 1,45 mounting hole

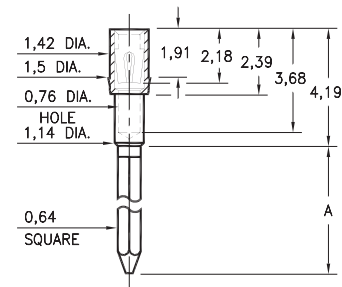


| Basic Part Number | # of Wraps | Length A |
|-------------------|------------|----------|
| 1702-2            | 2          | 9,4      |
| 1703-3            | 3          | 12,95    |

## 0038⇒0040/0066⇒0068

00XX-X-17-XX-30-XX-02-0

Press-fit in 1,45 mounting hole

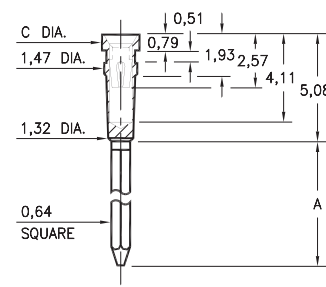


| Basic Part # | # of Wraps | Length A | Dia. C |
|--------------|------------|----------|--------|
| 0040-1       | 1          | 6,6      |        |
| 0039-2       | 2          | 9,14     | 1,83   |
| 0038-3       | 3          | 12,7     |        |
| 0068-1       | 1          | 6,6      |        |
| 0067-2       | 2          | 9,14     | 1,57   |
| 0066-3       | 3          | 12,7     |        |

## 0086/0088/0089

008X-X-17-XX-3X-XX-02-0

Press-fit in 1,45 mounting hole

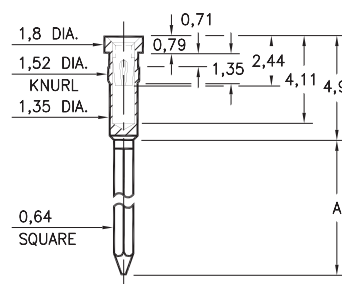


| Basic Part Number | # of Wraps | Length A |
|-------------------|------------|----------|
| 0089-2            | 2          | 9,4      |
| 0088-3            | 3          | 12,95    |
| 0086-4            | 4          | 16,0     |

## 1030⇒1036

103X-X-17-XX-3X-XX-02-0

Press-fit in 1,45 mounting hole

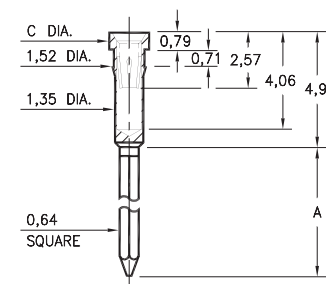


| Basic Part # | # of Wraps | Length A | Dia. C |
|--------------|------------|----------|--------|
| 1032-1       | 1          | 6,6      |        |
| 1031-2       | 2          | 9,14     | 1,83   |
| 1030-3       | 3          | 12,95    |        |
| 1036-1       | 1          | 6,6      |        |
| 1035-2       | 2          | 9,14     | 1,57   |
| 1034-3       | 3          | 12,95    |        |

## 1045

1045-3-17-XX-30-XX-02-0


Press-fit in 1,09 mounting hole

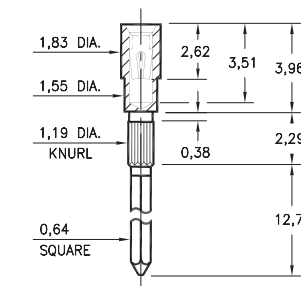

## 1040

1040-3-17-XX-30-XX-02-0

Press-fit in 1,42 mounting hole

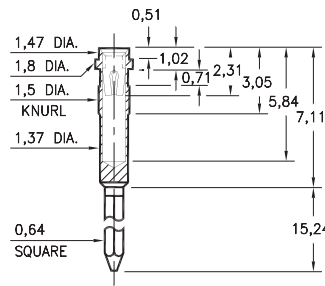

### SPECIFICATIONS:

**Shell Material:** Brass Alloy 360, 1/2 Hard

**Contact Material:** Beryllium Copper Alloy 172, HT

**Dimensions:** Millimeters

**Tolerances On:** Lengths: ± 0,13  
Diameters: ± 0,051  
Angles: ± 2°

RoHS-2  
2011/65/EU

**ORDER CODE:** XXXX - X - 17 - XX - XX - XX - 02 - 0

**BASIC PART #**

**SPECIFY SHELL FINISH:**

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 15 0,25µm GOLD OVER NICKEL (RoHS)

**SPECIFY CONTACT FINISH:**

- 02 2,54µm TIN/LEAD OVER NICKEL
- ◆ 84 2,54µm TIN OVER NICKEL (RoHS)
- ◆ 27 0,76µm GOLD OVER NICKEL (RoHS)

**SELECT CONTACT:**

**#30 or #32 CONTACT (DATA ON PAGE 253)**

(For alternate contact choices, see groups B and C on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com