

WATER-TIGHT Incandescent Indicators

with RETAINED O-RING SEALS – TWO TERMINALS - FULLY INSULATED

WATER-TIGHT, OIL-TIGHT, DUST-TIGHT ON THE FACE OF THE PANEL

For mounting in 15/32" clearance hole



T-1 3/4
MIDGET
FLANGE BASE

See lamp ratings
on page J.

MEET OR EXCEED ENVIRONMENTAL AND OPERATIONAL REQUIREMENTS
OF MIL-L-6723 AND MIL-L-3661B



177-8430-0931-503

MATERIALS AND FINISHES

- **Mounting Bushing:** Aluminum, black anodize finish. Optional—clear anodize finish.
- **Internal-tooth Lockwasher and Mounting Nut:** Steel, cadmium plated with yellow iridescent chromate finish.
- **Terminals:** Brass, hot tinned, with elongated slot.
- **Lens:** High impact plastic.

How to designate the Three Digit Part Number Suffix (—XXX)


Finish	Resistor	Hardware
5 — black anodize	0 — none	3 — watertight on the face of the panel
6 — clear anodize		

Example: 177-8430-0931-603 (clear anodize finish, no resistor, watertight construction).

177 SERIES

BASE PART NUMBERS

CAP PART NUMBERS

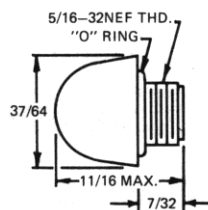


STOVEPIPE

177-0931-003
transparent

177-0971-003
translucent

FRONT MOUNTING

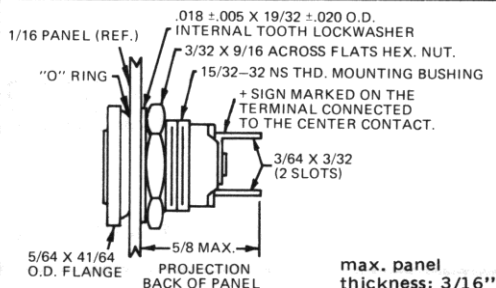

max. panel
thickness: 3/16"

177-8430-09-503

COMPLETE ASSEMBLY PART NUMBERS

177-8430-0931-503

177-8430-0971-503

Part numbers listed in this catalog designate products with RED lens.
For ordering lens colors other than red, consult chart on page 4C.

Order complete with lamp to be assured of receiving the indicator
light and correct lamp together for immediate use.

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.