




DUAL-IN-LINE HEADERS

SERIES 150, 153 • SOLDER TAIL AND WRAPOST • OPEN FRAME

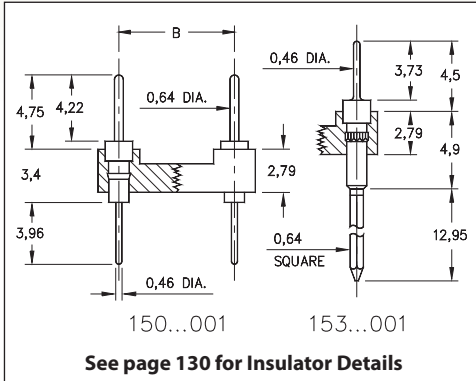

- Series 150 DIL Headers are equipped with 0,64 dia. pins MM #0290. See page 215 for details
- Series 153 DIL Headers have 3-level wraposts MM #5301. See page 227 for details
- Both series have 0,46 dia. solder tails which are pluggable into standard contacts
- Insulators are high temperature thermoplastic, suitable for all soldering operations
- For Electrical, Mechanical and Environmental Data, see page 264 for details

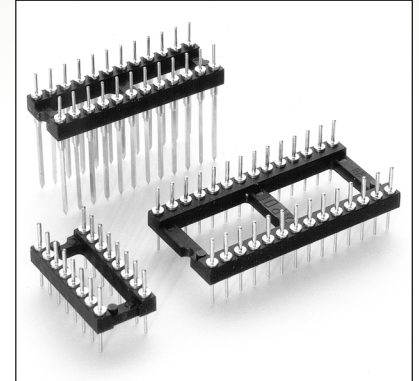

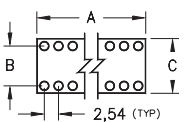Total number of pins				Quantity per tube	ORDERING INFORMATION						
	A	B	C		Solder Tail	3 Level Wrapost					
10	12,6	5,08	7,6	40	150-XX-210-00-001000	153-XX-210-00-001000					
4	5,0	7,62	10,1	102	150-XX-304-00-001000	153-XX-304-00-001000					
6	7,6	7,62	10,1	67	150-XX-306-00-001000	153-XX-306-00-001000					
8	10,1	7,62	10,1	50	150-XX-308-00-001000	153-XX-308-00-001000					
10	12,6	7,62	10,1	40	150-XX-310-00-001000	153-XX-310-00-001000					
14	17,7	7,62	10,1	29	150-XX-314-00-001000	153-XX-314-00-001000					
16	20,3	7,62	10,1	25	150-XX-316-00-001000	153-XX-316-00-001000					
18	22,8	7,62	10,1	22	150-XX-318-00-001000	153-XX-318-00-001000					
20	25,3	7,62	10,1	20	150-XX-320-00-001000	153-XX-320-00-001000					
22	27,8	7,62	10,1	18	150-XX-322-00-001000	153-XX-322-00-001000					
24	30,4	7,62	10,1	16	150-XX-324-00-001000	153-XX-324-00-001000					
28	35,5	7,62	10,1	14	150-XX-328-00-001000	153-XX-328-00-001000					
20	25,4	10,16	12,7	20	150-XX-420-00-001000	153-XX-420-00-001000					
22	27,8	10,16	12,7	18	150-XX-422-00-001000	153-XX-422-00-001000					
24	30,4	10,16	12,7	16	150-XX-424-00-001000	153-XX-424-00-001000					
28	35,5	10,16	12,7	14	150-XX-428-00-001000	153-XX-428-00-001000					
32	40,6	10,16	12,7	12	150-XX-432-00-001000	153-XX-432-00-001000					
24	30,4	15,24	17,7	16	150-XX-624-00-001000	153-XX-624-00-001000					
28	35,5	15,24	17,7	14	150-XX-628-00-001000	153-XX-628-00-001000					
32	40,6	15,24	17,7	12	150-XX-632-00-001000	153-XX-632-00-001000					
36	45,7	15,24	17,7	11	150-XX-636-00-001000	153-XX-636-00-001000					
40	50,8	15,24	17,7	10	150-XX-640-00-001000	153-XX-640-00-001000					
42	53,3	15,24	17,7	9	150-XX-642-00-001000	153-XX-642-00-001000					
48	60,9	15,24	17,7	8	150-XX-648-00-001000	153-XX-648-00-001000					
50	63,5	15,24	17,7	8	150-XX-650-00-001000	153-XX-650-00-001000					
52	66,0	15,24	17,7	7	150-XX-652-00-001000	153-XX-652-00-001000					
50	63,5	22,86	25,3	8	150-XX-950-00-001000	153-XX-950-00-001000					
52	66,0	22,86	25,3	7	150-XX-952-00-001000	153-XX-952-00-001000					
64	81,2	22,86	25,3	6	150-XX-964-00-001000	153-XX-964-00-001000					
					SPECIFY PLATING CODE XX =			10 	90	40 	
					Pin Plating 			0,25µm Au	5,08µm Sn/Pb	5,08µm Sn	

RoHS-2
2011/65/EU

XX=Plating Code
See Below



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com