


JTPQ00R (MS27497) — crimp wall mounting receptacle (back panel mounting)

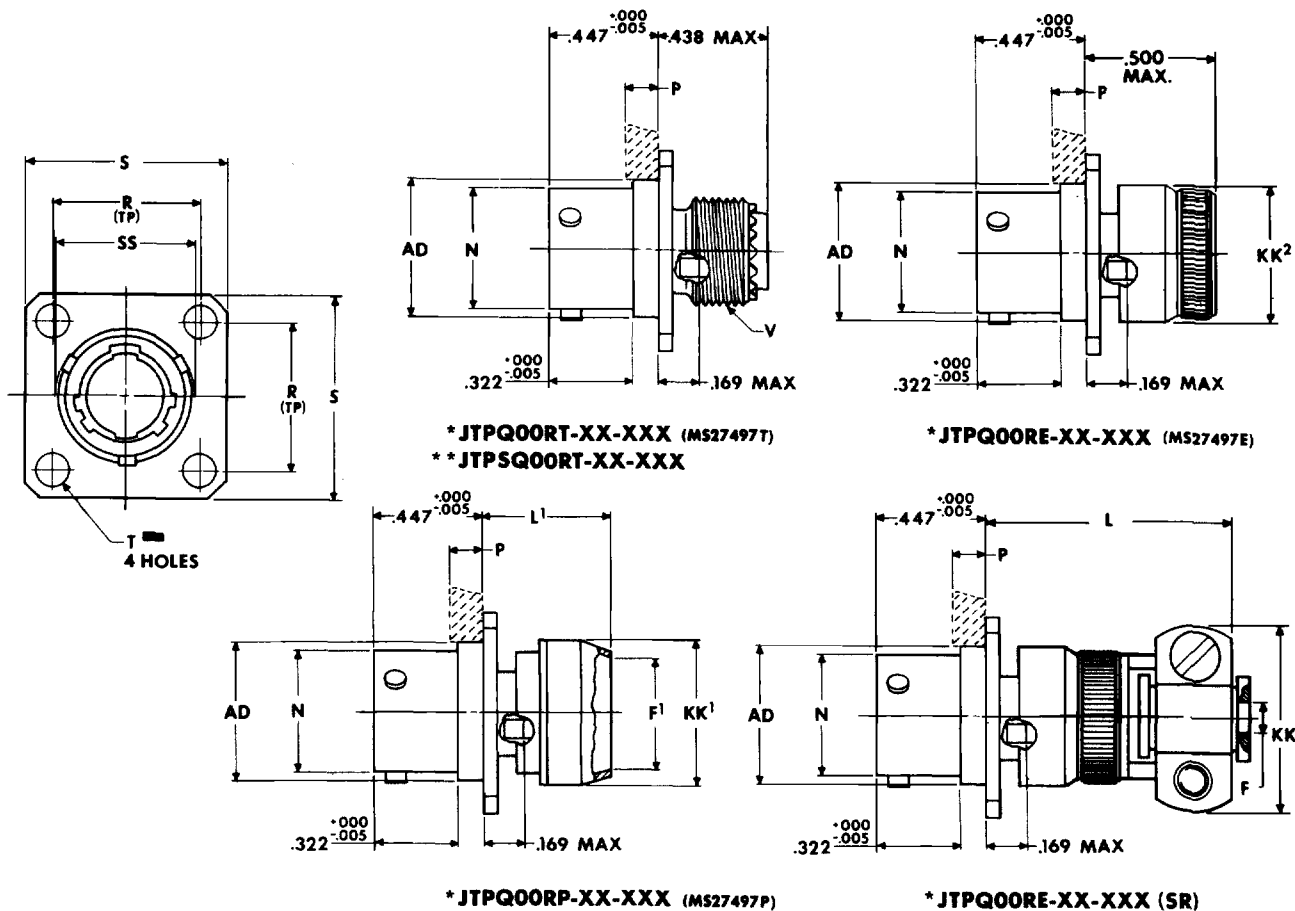

⌀ .005 DIA (M)

* To complete order number see page 47.

** High temperature version, to complete order number see page 47.

Shell Size	F Dia. $+.010$ $-.025$	F ¹ Dia. $+.010$ $-.010$	L Max.	L ¹ Max.	N Dia. $+.001$ $-.005$	P Max. Panel Thickness	R (TP)	S $±.016$	T Dia. $±.005$	V Thread UNEF Class 2A (Plated)	AD Dia. $±.005$	KK Max.	KK ¹ Dia. Max.	KK ² Dia. Max.	SS Dia. $+.000$ $-.016$
8	.125	.444	1.140	.468	.473	.142	.594	.812	.120	.4375-28	.516	.781	.625	.578	.563
10	.188	.558	1.140	.468	.590	.142	.719	.938	.120	.5625-24	.633	.844	.750	.703	.680
12	.312	.683	1.140	.468	.750	.142	.812	1.031	.120	.6875-24	.802	.969	.875	.828	.859
14	.375	.808	1.375	.468	.875	.142	.906	1.125	.120	.8125-20	.927	1.094	1.000	.953	.984
16	.500	.909	1.375	.468	1.000	.142	.969	1.219	.120	.9375-20	1.052	1.154	1.125	1.078	1.108
18	.625	1.034	1.375	.468	1.125	.142	1.062	1.312	.120	1.0625-18	1.177	1.406	1.250	1.203	1.233
20	.625	1.159	1.375	.468	1.250	.142	1.156	1.438	.120	1.1875-18	1.302	1.406	1.375	1.328	1.358
22	.750	1.284	1.516	.468	1.375	.142	1.250	1.562	.120	1.3125-18	1.427	1.594	1.500	1.453	1.483
24	.800	1.409	1.500	.540	1.500	.142	1.375	1.688	.147	1.4375-18	1.552	1.688	1.625	1.578	1.610

All dimensions for reference only.