


PIN RECEPTACLES

FOR 0,38 - 0,64 DIAMETER PINS

8964

8964-0-15-XX-30-XX-04-0


Press-fit in 1,45 mounting hole

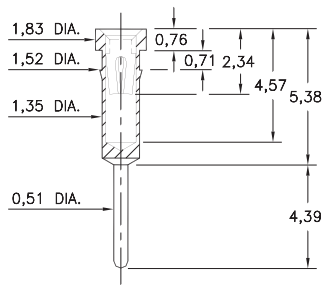

5342

5342-0-15-XX-35-XX-10-0


Solder mount in 1,3 min. mounting hole
Also available on 8mm wide carrier tape:
6,000 parts per 330mm reel
Order as: 5342-0-57-XX-35-XX-10-0

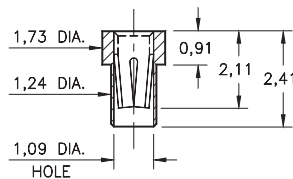

8857

8857-X-15-XX-32-XX-04-0

Press-fit in 1,45 mounting hole

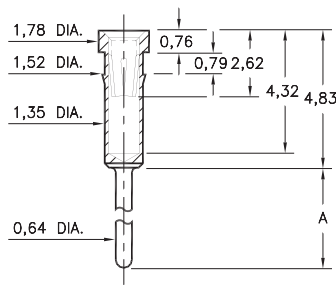


Basic Part Number	Length A
8857-0	7,9
8857-1	11,38
8857-2	14,96
8857-3	18,57
8857-4	22,12

8862/8877

88XX-0-15-XX-30-XX-04-0

Press-fit in 1,42 mounting hole

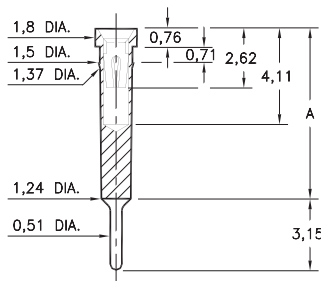


Basic Part Number	Length A
8862-0	7,62
8877-0	8,89

1334

1334-0-15-XX-30-XX-04-0


Press-fit in 1,45 mounting hole

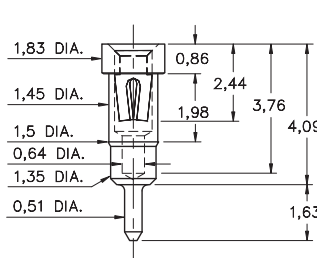

8855

8855-0-15-XX-30-XX-34-0


Press-fit in 1,45 mounting hole

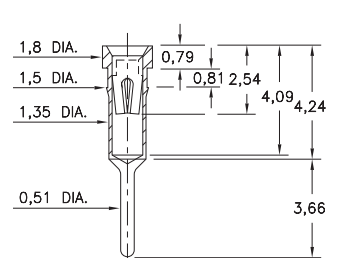

2954

2954-0-18-XX-30-XX-10-0


Press-fit in 1,45 mounting hole
Accepts wire sizes up to 0,71 dia.

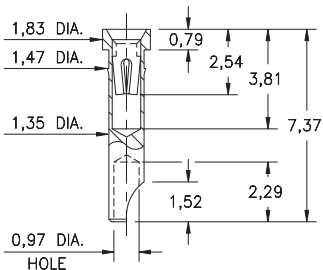

9363

9363-0-15-XX-35-XX-10-0


Solder mount in 1,45 min. mounting hole

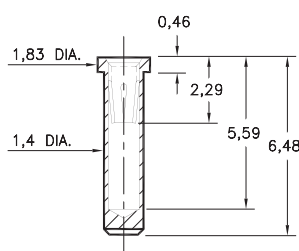

1023

1023-0-15-XX-30-XX-04-0


Press-fit in 1,55 mounting hole

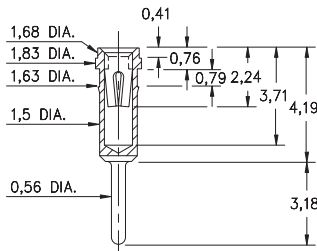

1701

1701-0-15-XX-30-XX-10-0

Press-fit in 1,45 mounting hole

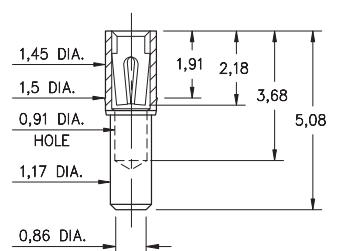

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: $\pm 0,13$

Diameters: $\pm 0,051$

Angles: $\pm 2^\circ$



ORDER CODE: XXXX - X - XX - XX - XX - XX - 10 - 0

BASIC PART #

SPECIFY SHELL FINISH:

01 5,08 μ m TIN/LEAD OVER NICKEL

◆ 80 5,08 μ m TIN OVER NICKEL (RoHS)

◆ 15 0,25 μ m GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

02 2,54 μ m TIN/LEAD OVER NICKEL

◆ 84 2,54 μ m TIN OVER NICKEL (RoHS)

◆ 27 0,76 μ m GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#30, #32 or #35 CONTACT (DATA ON PAGE 253 & 254)

(For alternate contact choices, see groups B and C on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com