

INTERCONNECTS

SERIES 442 • 2,54 GRID BOARD STACKING HEADERS • DOUBLE ROW STRIPS

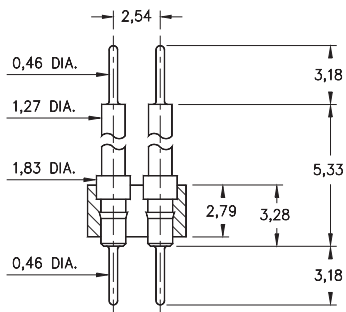


FIG. 1

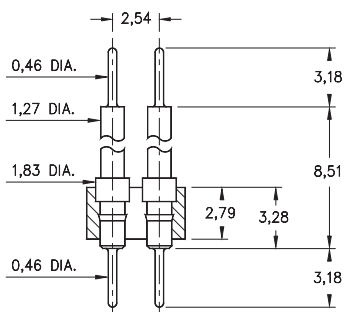


FIG. 2

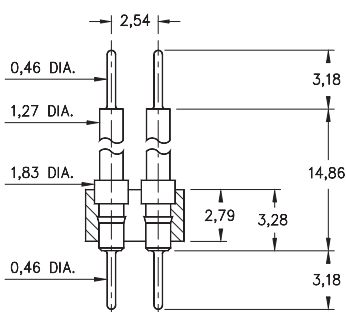


FIG. 3

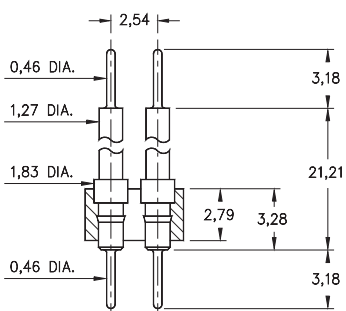


FIG. 4

- Series 442 interconnect header strips come in four heights with 0,46 dia. pluggable solder tails at both ends

442...591 uses pin #4259-1 (L = 5,33)


442...592 uses pin #4259-2 (L = 8,51)

442...593 uses pin #4259-3 (L = 14,86)

442...594 uses pin #4259-4 (L = 21,21)

See page 212 for details

- Insulators are high temperature thermoplastic, suitable for all soldering operations

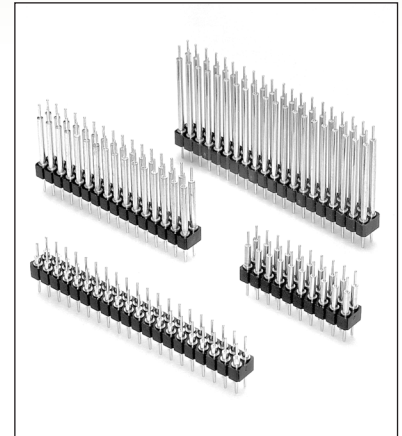

ORDERING INFORMATION

FIG. 1	Series 442...591	0,46 / 0,46 Dia. Solder Tails
	442-XX-2	-00-591000
	Specify number of pins	04-64
FIG. 2	Series 442...592	0,46 / 0,46 Dia. Solder Tails
	442-XX-2	-00-592000
	Specify number of pins	04-64
FIG. 3	Series 442...593	0,46 / 0,46 Dia. Solder Tails
	442-XX-2	-00-593000
	Specify number of pins	04-64
FIG. 4	Series 442...594	0,46 / 0,46 Dia. Solder Tails
	442-XX-2	-00-594000
	Specify number of pins	04-64
RoHS-2 2011/65/EU XX=Plating Code See Below For Electrical, Mechanical & Enviromental Data, See page 264		
SPECIFY PLATING CODE XX=		
Pin Plating		
10	90	40
0,25µm Au	5,08µm Sn/Pb	5,08µm Sn