
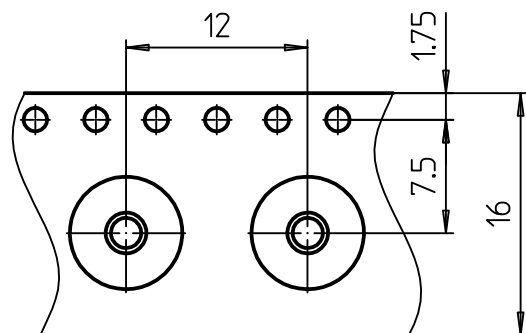
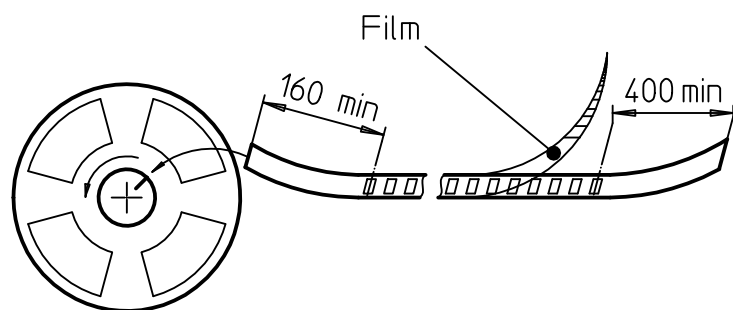


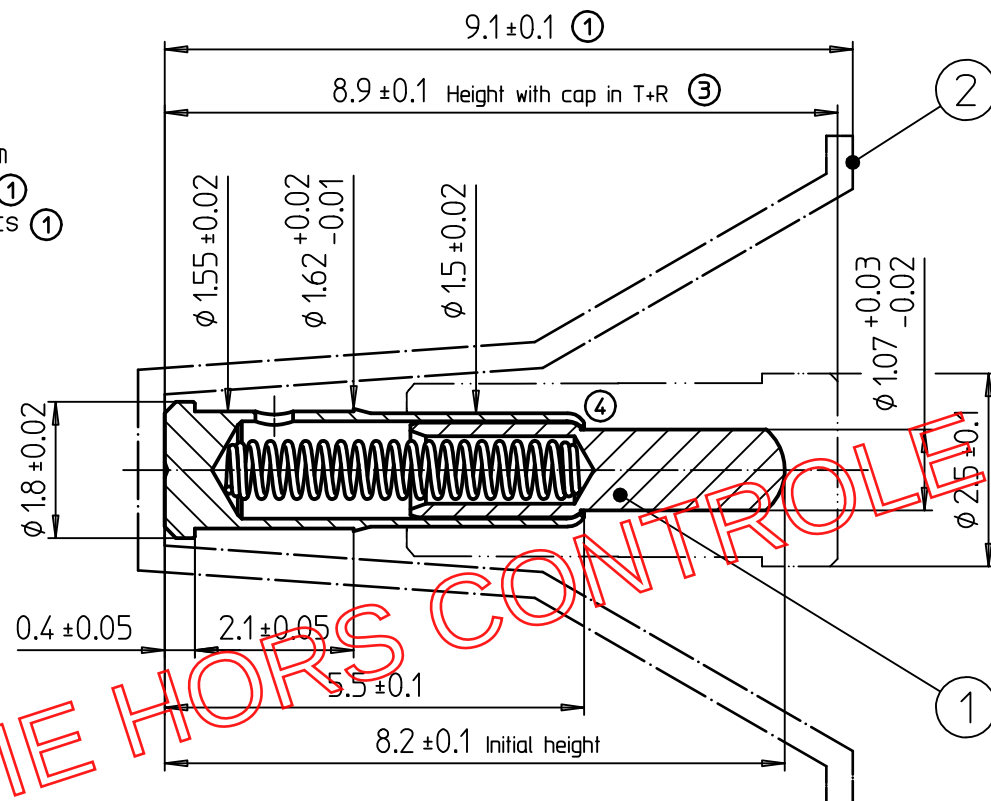

2:1

Packaging details :

- Reel diameter 330 mm
- Tape length 8.3 m ①
- Quantity per reel 600 pcs ①

MECHANICAL

Durability 100'000 cycles minimum
 Theoretical stroke S= 2.2 mm
 Recommended working level H= 6.2 to 7.2 mm
 Spring forces F1= 0.2 N initial (indicative value)
 F2= 0.3 N ±0.15 N at H= 7.2 mm

Forces are measured in decompression mode

ELECTRICAL (TYPICAL VALUE)

Current per contact max continuously 1 A
 max peak 2 A
 Contact resistance 30 mOhm in static mode within recommended working height after full life

ENVIRONMENTAL

Operating temperature : -25°C / +125°C
 Storage temperature : -40°C / +125°C
 Relative humidity : 5% / 95%

2	Packaging 0-98-00037	.	.
1	Spring-loaded contact 90013-AS-04	1	.
Pos.	Désignation	Qté	Matière - Protection
R1 le 03.09.15 (5232) R3 le 15.02.16 (6041)	R2 le 15.02.16 (6004) R4 le 23.02.17 (7026)	P14.20.09 / 15-050	
SPRING-LOADED CONTACT			Remplace: Remplacé par: Dessiné 27.01.2015 S.Humbert Contrôlé N° dessin 90013-AS-02 Révision R4