


# PIN RECEPTACLES

FOR 0,38 - 0,64 DIAMETER PINS

## 1802/3802/4030/8866

XXXX-0-15-XX-43-XX-04-0

Press-fit in 1,45 mounting hole

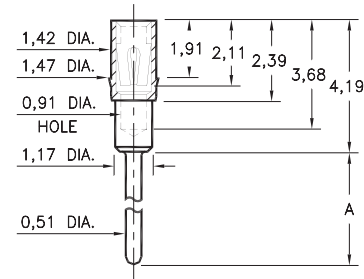


| Basic Part Number | Length A |
|-------------------|----------|
| 1802-0            | 3,18     |
| 3802-0            | 4,19     |
| 8866-0            | 19,69    |
| 4030-0            | 20,70    |

## 1803/1805/1808/3805

XXXX-0-15-XX-XX-XX-04-0

Press-fit in 1,45 mounting hole

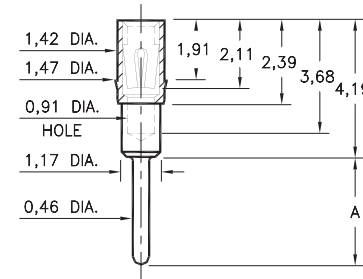


| Basic Part Number | Length A |
|-------------------|----------|
| 1808-0            | 2,54     |
| 1803-0            | 3,68     |
| 1805-0            | 5,41     |
| 3805-0            | 9,98     |

## 1804/1806

180X-0-15-XX-43-XX-04-0

Press-fit in 1,45 mounting hole

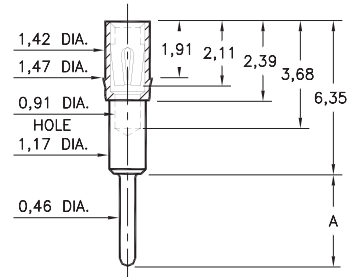


| Basic Part Number | Length A |
|-------------------|----------|
| 1804-0            | 2,03     |
| 1806-0            | 2,92     |

## 1807

1807-0-15-XX-43-XX-04-0


Press-fit in 1,45 mounting hole

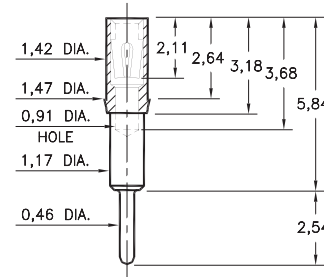

## 8830

8830-15-XX-22-XX-10-0


Solder mount in 1,45 min. mounting hole

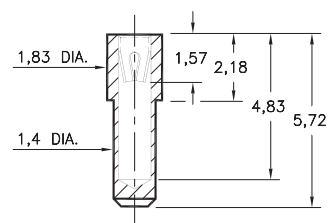

## 8363

8363-0-15-XX-35-XX-10-0


Solder mount in 1,45 min. mounting hole

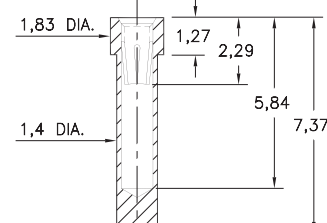

## 4622

4622-0-15-XX-30-XX-10-0


Hex press-fit in 1,35 plated through-hole

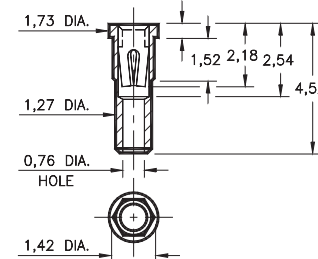

## 6252

6252-0-15-XX-32-XX-10-0

Hex press-fit in 1,45 plated through-hole

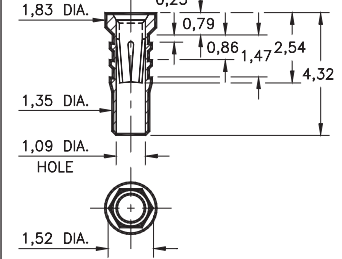

### SPECIFICATIONS:

**Shell Material:** Brass Alloy 360, 1/2 Hard

**Contact Material:** Beryllium Copper Alloy 172, HT

**Dimensions:** Millimeters

**Tolerances On:** Lengths:  $\pm 0,13$

Diameters:  $\pm 0,051$

Angles:  $\pm 2^\circ$



**ORDER CODE:** XXXX - X - 15 - XX - XX - XX - 0

**BASIC PART #**

**SPECIFY SHELL FINISH:**

01 5,08 $\mu$ m TIN/LEAD OVER NICKEL

◆ 80 5,08 $\mu$ m TIN OVER NICKEL (RoHS)

◆ 15 0,25 $\mu$ m GOLD OVER NICKEL (RoHS)

**SPECIFY CONTACT FINISH:**

02 2,54 $\mu$ m TIN/LEAD OVER NICKEL

◆ 84 2,54 $\mu$ m TIN OVER NICKEL (RoHS)

◆ 27 0,76 $\mu$ m GOLD OVER NICKEL (RoHS)

**SELECT CONTACT:**

#22, #30, #32 or #43 CONTACT (DATA ON PAGES 252, 253 & 254)

(For alternate contact choices, see groups B and C on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com