


PIN RECEPTACLES

**FOR .015" - .020" DIAMETER PINS (#11 CONTACT)
AND .015" - .022" DIAMETER PINS (#21 CONTACT)
(SEE SPECIFIC CONTACT RANGE ON PAGE 251)**

8467

8467-0-15-XX-21-XX-04-0


Hex press-fit in .036 plated through-hole

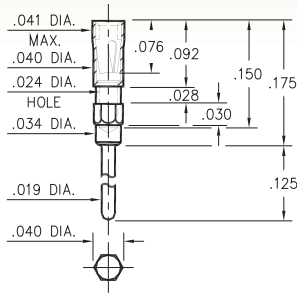

6192

6192-0-15-XX-21-XX-04-0


Square press-fit in .032 plated through-hole

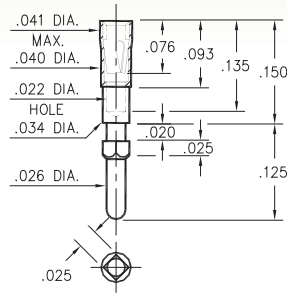

9553

9553-0-15-XX-X1-XX-04-0


Hex press-fit in .041 plated through-hole

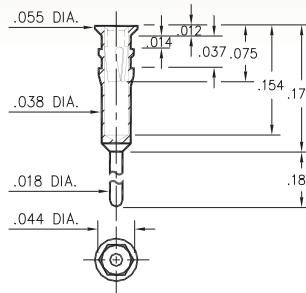

5531

5531-0-15-XX-21-XX-10-0


Hex press-fit in .041 plated through-hole

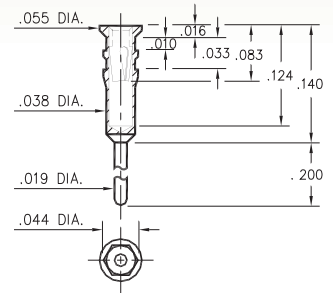

7553

7553-0-15-XX-11-XX-10-0


Hex press-fit in .041 plated through-hole

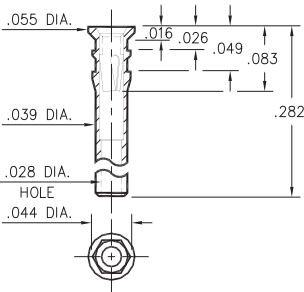

9407

9407-0-15-XX-11-XX-10-0


Solder mount in .040 min. mounting hole

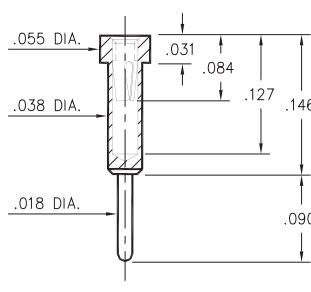

9462

9462-0-15-XX-21-XX-04-0


Hex press-fit in .043 plated through-hole

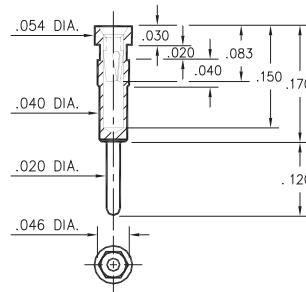

1147

1147-0-18-XX-21-XX-10-0


Press-fit in .043 min. mounting hole
Accepts wire sizes up to .014" dia.

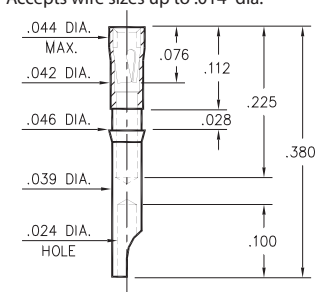

3061

3061-0-19-XX-21-XX-10-0


Wire Crimp Termination. Accepts wire sizes 28 AWG Max. / 32 AWG Min.

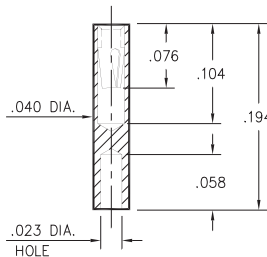

0579

0579-0-15-XX-X1-XX-10-0


Press-fit in .040 mounting hole

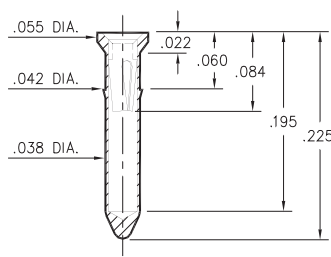

8874

8874-0-15-XX-11-XX-10-0


Bottom entry surface mount
See page 152 for application details

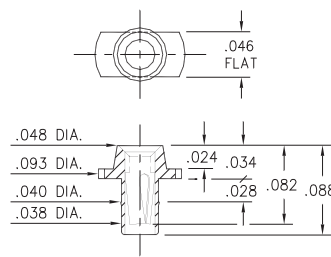

0613

0613-0-15-XX-21-XX-10-0

Press-fit in .047 mounting hole

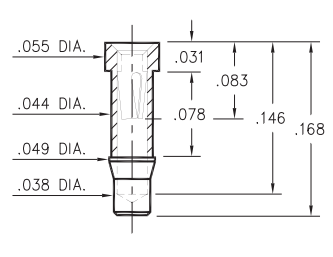

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Inches

Tolerances On: Lengths: $\pm .005$

Diameters: $\pm .002$

Angles: $\pm 2^\circ$

RoHS-2
2011/65/EU

ORDER CODE: XXXX - X - 1X - XX - XX - XX - 0

BASIC PART #

SPECIFY SHELL FINISH:

01 200 μ " TIN/LEAD OVER NICKEL

80 200 μ " TIN OVER NICKEL (RoHS)

15 10 μ " GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

02 100 μ " TIN/LEAD OVER NICKEL

84 100 μ " TIN OVER NICKEL (RoHS)

27 30 μ " GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#11 or #21 CONTACT (DATA ON PAGE 251)

(For alternate contact choices, see group A on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com