


REV.	ECN NO.	DATE	SIGN	DESCRIPTION
A	Initial Released	2020/11/25	Ruru	Old Item No. CX-04BCM32-7002

☉ Laser Mark:
YYYY = Year
WW = Week

Cable Joiner Housing Part Number
FC-001BNGY-700X

M32x1.0

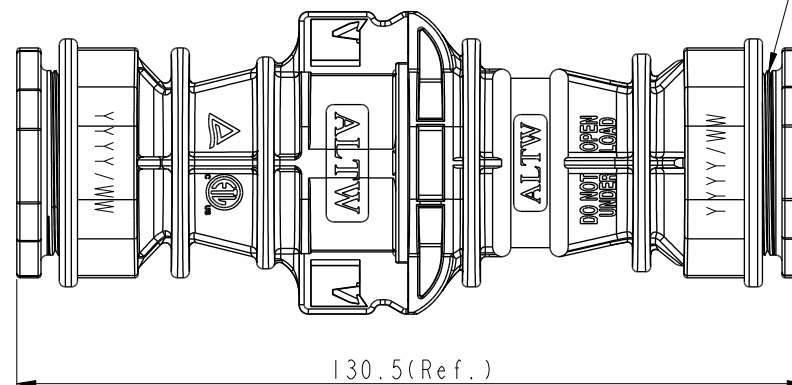

Note:

- * Waterproof Rate: IP67, Mated
- * Connector: Thermoplastic, Black
- * Butt Pin: Copper alloy
- * Gasket: Rubber, Gray
- * Disassembly-Using the Unlock tool.
- * Operating Temperature : -40~+105°C
- * Withstanding Voltage : 6KV
- * Pollution Degree : III
- * Cable OD Range: 12mm~10mm
- * Wire Range: 10#~12#(4mm²~6mm²)
- * Avoid oil and gasoline
- * Recommended sealing Nut torque
Minimum: 25Kgf-cm

UNIT:mm
TOLERANCE
±0.5 mm

TITLE FICX, 4, 1, Field Installable Crimp, Gray			
SCALE 4:5	SIZE A4	SHEET 1 OF 1	
REV. A	WC-REV. B.3	☉ Inspection item	

Amphenol LTW
安費諾亮泰企業股份有限公司

ITEM NO FC-04IBCGY-7002	DRAWN BY Ruru	DATE 2020-11-25
DWG NO FC-04IBCGY-7002	CHECKED BY Rita	DATE 2020-11-25
CUSTOMER ALTW	APPROVED BY Max	DATE 2020-11-25