

Dialight


550 SERIES

5mm LED CBI®

Circuit Board Indicator Sloped Back Housing with Standoffs


FEATURES / BENEFITS

- ▲ Multiple CBIs form horizontal LED arrays on 6.35mm (0.250") center-lines.
- ▲ High contrast, UL 94 V-0 rated, black housing
- ▲ Oxygen index: 32%
- ▲ Polymer content: PBT, 0.206 g
- ▲ Housing stand-offs facilitate PCB cleaning
- ▲ Solderability per MIL-STD-202F, method 208F
- ▲ LEDs are safe for direct viewing per IEC 825-1, EN-60825-1
- ▲ Compatible with: 550-xx07 Dual Block and 550-xx07-004 Quad Block

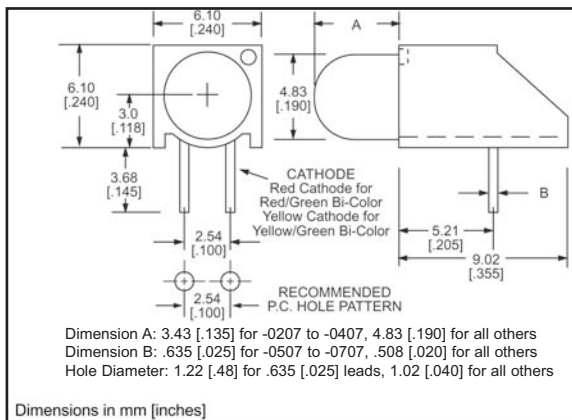

Standard Polarity shown in drawing: Cathode right

PART NUMBER ORDERING CODE

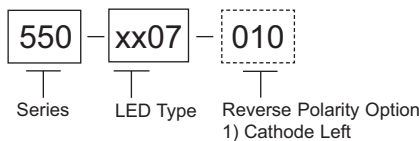

Contact factory for information on custom color combinations.

TOLERANCE NOTE: As noted, otherwise:

- LED Protrusion: $\pm 0.41\text{mm}$ [± 0.016]
- CBI Housing: $\pm 0.20\text{mm}$ [± 0.008]

To order any of the 550-xx07 part numbers with Reverse Polarity (Cathode Left), please add -010 to the part numbers shown above.



A4703



ISO 9001

Dialight Corporation

1501 Route 34 South • Farmingdale, NJ 07727 USA
Tel: (1) 732-919-3119 • Fax: (1) 732-751-5778 • www.dialight.com

a Roxboro Group Company

MDEA550X001_A