



# DUAL-IN-LINE HEADERS

## SERIES 162, 862 • SHRINK DIP HEADER AND STRIPS, SOLDER TAIL

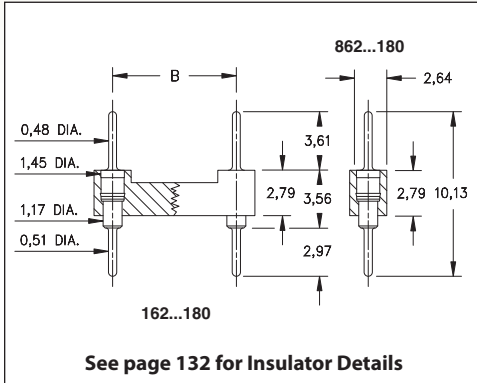

- High density DIP headers & strips for adapters and board stacking applications with 1,78 lead spacing
- Series 162 DIP headers and Series 862 strip headers use MM #6218 pins. See page 208 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations
- For Electrical, Mechanical and Environmental Data, see page 264 for details

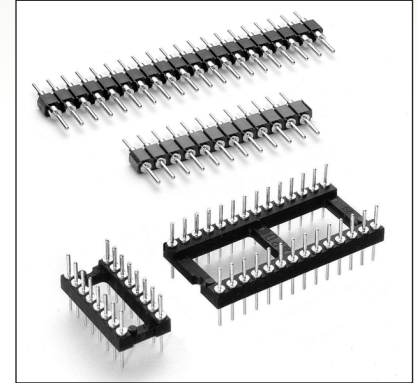

| Total number of pins             |       |       |       | Quantity per tube | ORDERING INFORMATION                                                                   |              |           |  |  |
|----------------------------------|-------|-------|-------|-------------------|----------------------------------------------------------------------------------------|--------------|-----------|--|--|
|                                  | A     | B     | C     |                   |                                                                                        |              |           |  |  |
| 16                               | 14,53 | 7,62  | 9,91  | 35                | 162-XX-316-00-180000                                                                   |              |           |  |  |
| 28                               | 25,20 | 10,16 | 12,45 | 20                | 162-XX-428-00-180000                                                                   |              |           |  |  |
| 30                               | 26,97 | 10,16 | 12,45 | 18                | 162-XX-430-00-180000                                                                   |              |           |  |  |
| 48                               | 42,98 | 10,16 | 12,45 | 12                | 162-XX-448-00-180000                                                                   |              |           |  |  |
| 20                               | 18,08 | 15,24 | 17,53 | 28                | 162-XX-620-00-180000                                                                   |              |           |  |  |
| 28                               | 25,20 | 15,24 | 17,53 | 20                | 162-XX-628-00-180000                                                                   |              |           |  |  |
| 40                               | 35,86 | 15,24 | 17,53 | 14                | 162-XX-640-00-180000                                                                   |              |           |  |  |
| 42                               | 37,64 | 15,24 | 17,53 | 13                | 162-XX-642-00-180000                                                                   |              |           |  |  |
| 48                               | 42,98 | 15,24 | 17,53 | 12                | 162-XX-648-00-180000                                                                   |              |           |  |  |
| 52                               | 46,53 | 15,24 | 17,53 | 11                | 162-XX-652-00-180000                                                                   |              |           |  |  |
| 56                               | 50,09 | 15,24 | 17,53 | 10                | 162-XX-656-00-180000                                                                   |              |           |  |  |
| 64                               | 57,20 | 15,24 | 17,53 | 9                 | 162-XX-664-00-180000                                                                   |              |           |  |  |
| 68                               | 60,76 | 15,24 | 17,53 | 8                 | 162-XX-668-00-180000                                                                   |              |           |  |  |
| 64                               | 57,20 | 19,05 | 21,34 | 8                 | 162-XX-764-00-180000                                                                   |              |           |  |  |
|                                  |       |       |       |                   | <b>SINGLE ROW STRIP HEADER</b><br>If desired, we will supply any length up to 21 pins. |              |           |  |  |
| 21                               | 37,64 | ---   | 2,64  | ---               | 862-XX-121-00-180000                                                                   |              |           |  |  |
| <b>SPECIFY PLATING CODE XX =</b> |       |       |       |                   | 10 ◆                                                                                   | 90           | 40 ◆      |  |  |
| Pin Plating                      |       |       |       |                   | 0,25µm Au                                                                              | 5,08µm Sn/Pb | 5,08µm Sn |  |  |

XX=Plating Code  
See Below

RoHS-2  
2011/65/EU

