
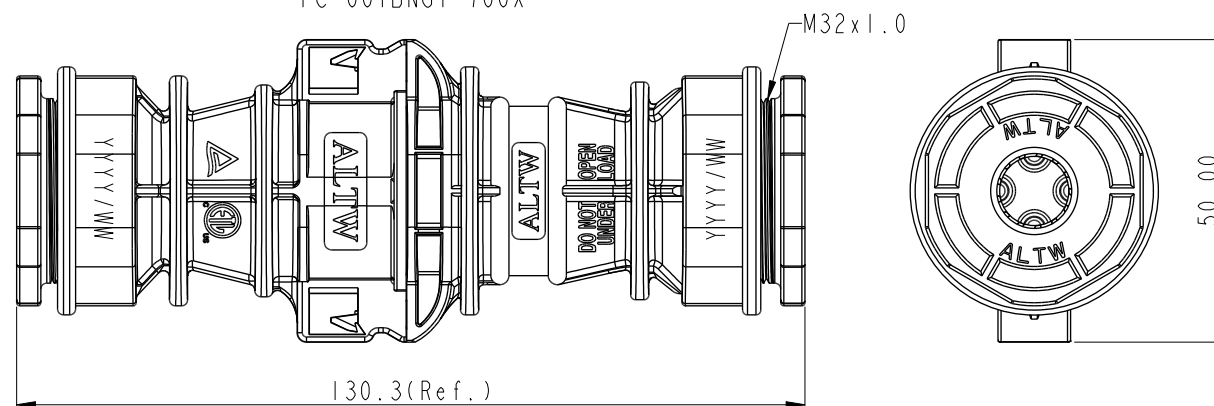


REV.	ECN NO.	DATE	SIGN	DESCRIPTION
A	Initial Released	2020/11/25	Ruru	Old Item No. CX-04BBM32-7001

☉ Laser Mark:
YYYY = Year
WW = Week

Cable Joiner Housing Part Number
FC-001BNGY-700X

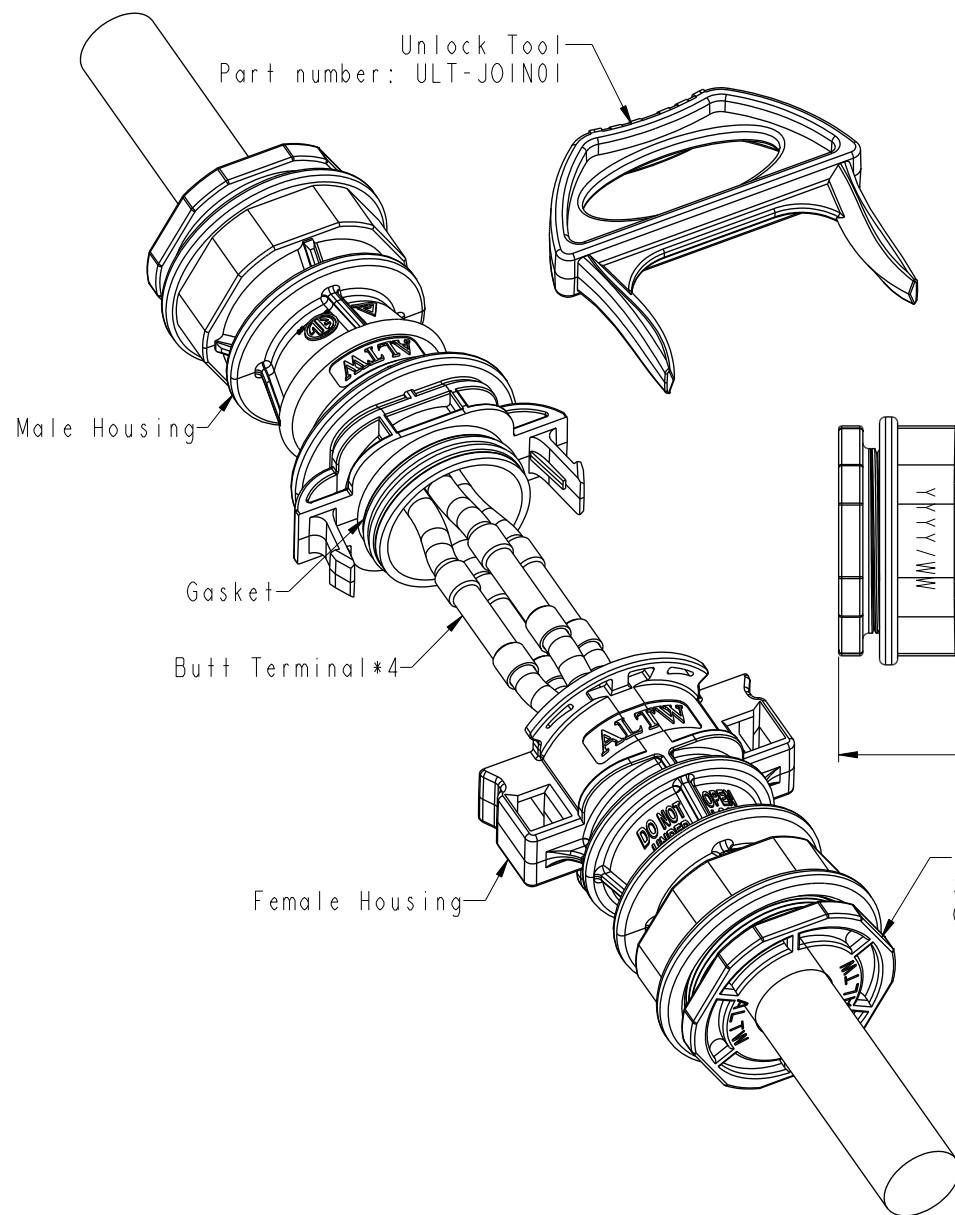

Note:

- * Waterproof Rate: IP67, Mated
- * Connector: Thermoplastic, Black
- * Butt Pin: Copper alloy
- * Gasket: Rubber, Gray
- * Disassembly-Using the Unlock tool.
- * Operating Temperature : -40~+105°C
- * Withstanding Voltage : 6KV
- * Pollution Degree : III
- * Cable OD Range: 10mm~08mm
- * Wire Range: 14#~16#(2.5mm²~1mm²)
- * Avoid oil and gasoline
- * Recommended sealing Nut torque
Minimum: 25Kgf-cm

- * FC-001BNGY-700X
UL 6703A & TUV 2pfg 1915
- * Butt Terminals
UL 486A/B

UNIT:mm		 	TITLE FICX, 4, 1, Field Installable Crimp, Gray			ITEM NO FC-04IBCGY-7003		DRAWN BY Ruru		DATE 2020-11-25		
TOLERANCE ± 0.5 mm												
			SCALE 4:5	SIZE A4	SHEET 1	OF 1	DWG NO FC-04IBCGY-7003		CHECKED BY Rita		DATE 2020-11-25	
			REV. A	WC-REV. B.4	QC: Inspection item							
Amphenol LTW 安費諾亮泰企業股份有限公司						CUSTOMER ALTW		APPROVED BY Max		DATE 2020-11-25		