

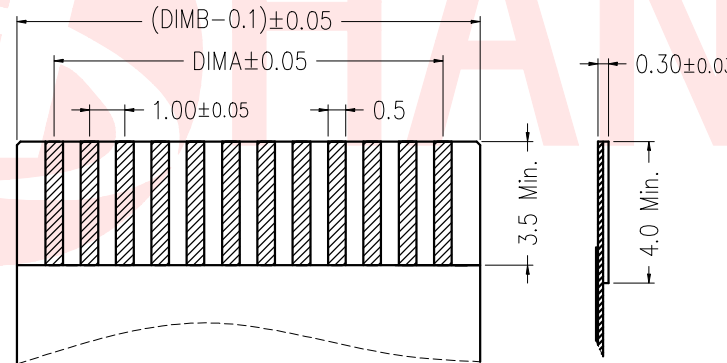
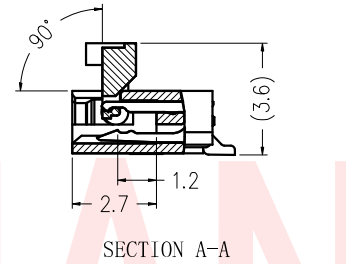
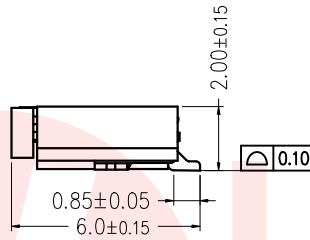
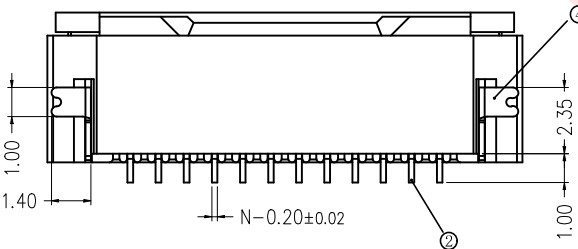
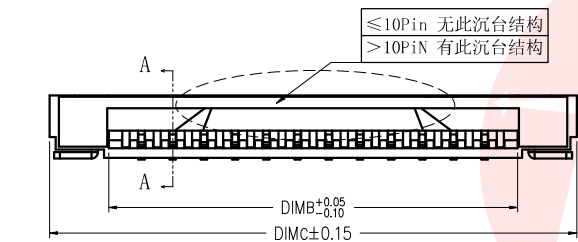
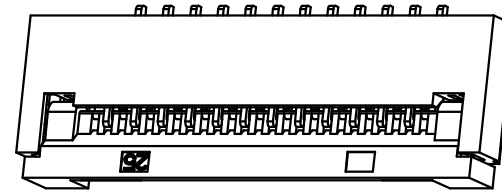


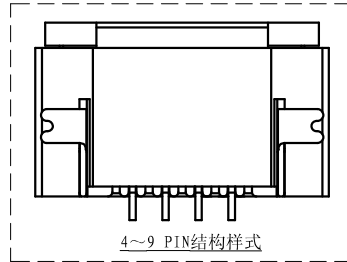


REV.	ECN NO OR DESCRIPTION	REVISED	DATE

序号	品名	材质
①	0.5掀盖胶芯 (H2.0)	LCP UL94V-0 本色
②	0.5掀盖端子 (H2.0)	铜合金/表面镀锡
③	0.5掀盖后盖 (H2.0)	LCP UL94V-0 黑色
④	0.5掀盖焊片 (H2.0)	铜合金/表面镀锡

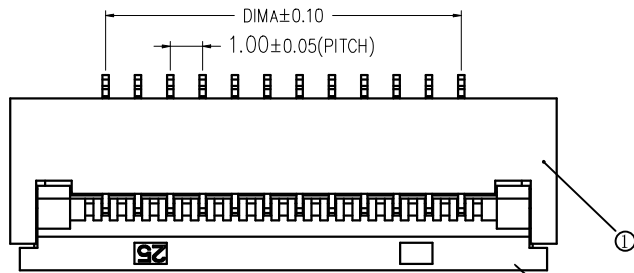

适用扁平线(Applicable Flat Cable)

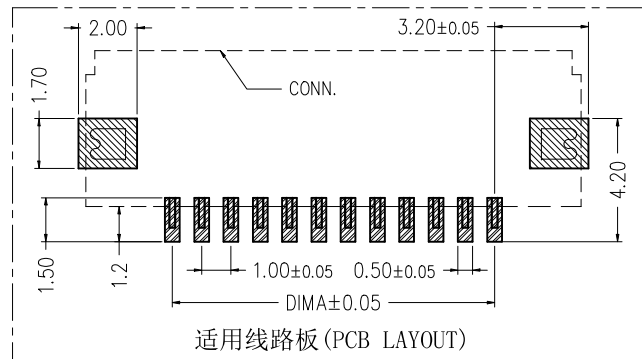

技术指标:

- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
- 温度范围: -25° C~85° C.
- 额定电压: 50V, AC/DC(等效)。
- 接触电阻: ≤0.03Ω.
- 绝缘电阻: ≥500MΩ

TABLE:

CSG PART NO.	PIN#	DIM.A	DIM.B	DIM.C
HB-FPC-10FGXJ-H202P	2PIN	1.00	3.10	6.90
HB-FPC-10FGXJ-H203P	3PIN	2.00	4.10	7.90
HB-FPC-10FGXJ-H204P	4PIN	3.00	5.10	8.90
HB-FPC-10FGXJ-H205P	5PIN	4.00	6.10	9.90
HB-FPC-10FGXJ-H206P	6PIN	5.00	7.10	10.90
HB-FPC-10FGXJ-H207P	7PIN	6.00	8.10	11.90
HB-FPC-10FGXJ-H208P	8PIN	7.00	9.10	12.90
HB-FPC-10FGXJ-H209P	9PIN	8.00	10.10	13.90
HB-FPC-10FGXJ-H2010P	10PIN	9.00	11.10	14.90
HB-FPC-10FGXJ-H2011P	11PIN	10.00	12.10	15.90
HB-FPC-10FGXJ-H2012P	12PIN	11.00	13.10	16.90
HB-FPC-10FGXJ-H2013P	13PIN	12.00	14.10	17.90
HB-FPC-10FGXJ-H2014P	14PIN	13.00	15.10	18.90
HB-FPC-10FGXJ-H2015P	15PIN	14.00	16.10	19.90
HB-FPC-10FGXJ-H2016P	16PIN	15.00	17.10	20.90
HB-FPC-10FGXJ-H2017P	17PIN	16.00	18.10	21.90
HB-FPC-10FGXJ-H2018P	18PIN	17.00	19.10	22.90
HB-FPC-10FGXJ-H2019P	19PIN	18.00	20.10	23.90
HB-FPC-10FGXJ-H2020P	20PIN	19.00	21.10	24.90
HB-FPC-10FGXJ-H2021P	21PIN	20.00	22.10	25.90
HB-FPC-10FGXJ-H2022P	22PIN	21.00	23.10	26.90
HB-FPC-10FGXJ-H2023P	23PIN	22.00	24.10	27.90
HB-FPC-10FGXJ-H2024P	24PIN	23.00	25.10	28.90
HB-FPC-10FGXJ-H2025P	25PIN	24.00	26.10	29.90
HB-FPC-10FGXJ-H2026P	26PIN	25.00	27.10	30.90
HB-FPC-10FGXJ-H2027P	27PIN	26.00	28.10	31.90
HB-FPC-10FGXJ-H2032P	32PIN	31.00	33.10	36.90

UNLESS OTHERWISE
SPECIFIED TOLERANCES

DECIMALS: ANGLES:
X :±0.30 X :±2°
X.X :±0.20 X.X :±1°
X.XX :±0.10



东莞市汉博电子科技有限公司
DONGGUAN HANBO TECHNOLOGY CO., LTD

TITLE	1.0Pitch掀盖卧式下接 (H=2.0)			
DWN	xiong	PART NO.	HB-FPC-10FGXJ-H20NP	
CHKD	lee	SCALE:1:1	UNIT: mm	
APVD	wang	SIZE: A4	SHEET:10F 1	REV: A4
CUSTOMER COPY				