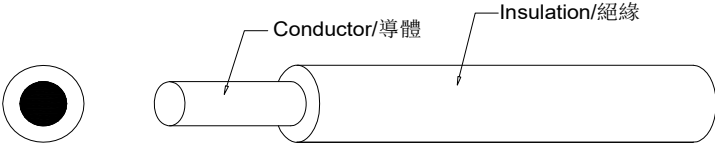


BWAY Cable & Wire Ltd

SPECIFICATION

NO: N0NL28TSxS2C114

Rev/版本:1

Construct map/構造圖		Color Code/芯線顏色
		x: 0=Black/黑色, 1=Brown/棕色, 2=Red/红色 3=Orange/橙色, 4=Yellow/黄色, 5=Green/绿色, 6=Blue/蓝色 7=Purple/紫色, 8=Gray/灰色, 9=White/白色
Cable Spec/電線規格	N0NL 28AWG(7/0.12TS) Wire Silicone OD:0.80mm	
Construction/構造	Item/項目	Spec show/規格說明
Conductor/導體	Material/材料	Stranded Tinned Copper/镀锡铜绞线
	Construction/構造	7/0.12±0.008mm
Insulation/絕緣	Material/材料	Silicone /硅胶
	Diameter/直徑	0.80±0.10mm
Filling/填充	Material/材料	/
	Construction/構造	/
Talcum/过粉	Material/材料	/
Package/包帶	Material/材料	/
	Overlap/重疊率	/
Drain Wire/地線	Material/材料	/
	Construction/構造	/
Shield/纏繞	Material/材料	/
	Construction/構造	/
	Coverage/遮蔽率	/
Jacket/外被	Material/材料	/
	Diameter/直徑	/
	Jacket Color/外被顏色	/
Marking/印字	/	
Electrical Characteristics (電氣性能)		Physical Properties (物理性能)
1.Rated Tem: +200°C		1.Flame test: /
2.Rated Voltage:300V		2.Tensile force: 0.35KG/MM ²
3.Spark Test:3KV		3.Elongation : 100%
4.Con.Resistance:≤239Ω/KM(at 20°C)		
Above all raw materials meet the RoHS environmental protection requirements/以上所有原材料符合RoHS環保要求		

Approved By(核准):Man

Checked By(審核): Arong

Filled By(制定):Yang.

Date(日期):Feb-24-2025