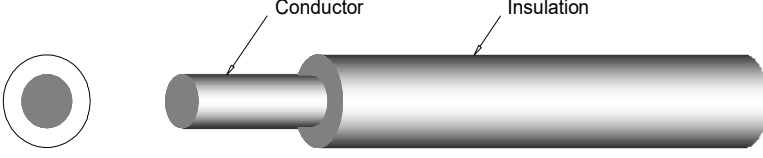


BWAY Cabel & Wire Ltd

SPECIFICATION

NO: N0NL28TSxA1

Rev/版本: 1

Construct map/構造圖		Color/顏色
		x: 0:Black/黑色, 1:Brown/棕色, 2:Red/红色, 3:Orange/橙色, 4:Yellow/黄色, 5:Green/绿色, 6:Blue/蓝色, 7:Purple/紫色, 8:Gray/灰色 9:White/白色, A:Pink
Cable Spec/電線規格	UL1571 28AWG(7/0.127TS) OD:0.60mm	
Construction/構造	Item/項目	Spec Show/規格說明
Conductor/導體	Material/材料	Stranded Tinned Copper/鍍錫銅絞線
	Construction/構造	7/0.127±0.008mm
Insulation/絕緣	Material/材料	45P PVC (UL105°C)
	Diameter/直徑	0.60±0.05mm
Drain Wire/地線	Material/材料	/
	Construction/構造	/
Shield/屏蔽	Material/材料	/
	Construction/構造	/
	Coverage/遮蔽率	/
Jacket/外被	Material/材料	/
	Diameter/直徑	/
	Jacket Color/外被顏色	/
Marking/印字	No Marking/无印字	
Electrical Characteristics (電氣性能)		Physical Properties (物理性能)
1.Rated Tem: 105°C		
2.Rated Voltage: 30V		
Above all raw materials meet the RoHS environmental protection requirements/以上所有原材料符合RoHS環保要求		

Approved By(核 准):Nicki

Checked By(審核):Arong

Filled By(制定):Dive.

Date(日期):Aug.-13-2021

