
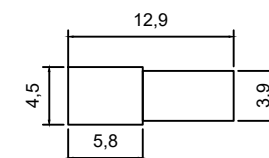
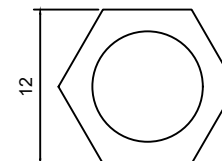
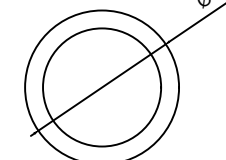
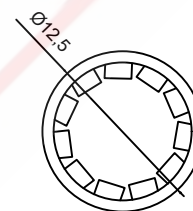
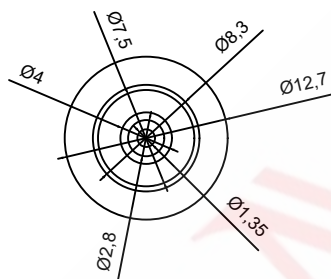


Technical Requirements:

 
1. Frequency: $0 \sim 3\text{GHz}$
2. Impedance: $50\ \Omega$
3. Voltage Standing Wave Ratio (VSWR): ≤ 1.35
4. Operating Voltage: 500V
5. Withstand Voltage: 1500V
6. Insulation Resistance: $\geq 5000\text{M}\Omega$
7. Contact Resistance:
 - Inner Conductor: $\leq 1.5\text{m}\Omega$
 - Outer Conductor: $\leq 1\ \Omega$
8. Insertion Loss: $\leq 0.3\text{dB}$

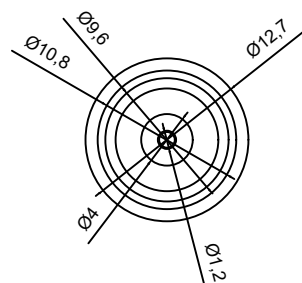

螺母3.0. 齿垫1.2 胶圈0.9. 套管

TNC-KY-315-L0-N

- Surface treatment镀层:亮镍
- Pin position脚位:垂直
- Length体长:31.55mm
- Product number编号:KY-1.5开窗
- Product series系列:TNC同轴射频天线座

FIRST VIEW

The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts.
WWW.KKK-JP.COM

TITLE:	
--------	--

TNC-KY1.5 3.155MM 垂直 开窗2.5

of DWG NO: TNCKY15-P001

PART NO: TNCKY15-190052

MODEL NO: TNC-KY-315-L0-N

NAME:	TNC
	COAXIAL RF CONNECTOR

SAMZO COMPONENTS
Electronic switch and connector manufacturer