
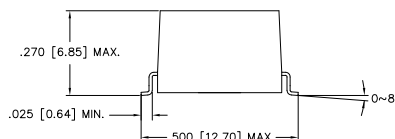
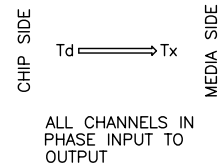


- Series/Type: **HMU1228NLT**

OCL	Turns Ratio	Insertion Loss			Return Loss (Z out = 100 ohms)		Working Voltage
		1-60 MHz	80MHz	125MHz	4MHz	30-80MHz	
150uH(min) 370uH(max)	1CT :1CT±2%	-1.0dB Max	-1.25dB TYP	-3.0dB Max	-16dB Min	-14+20*log(f/30)dB Min	1000 Vdc

SCHEMATICS


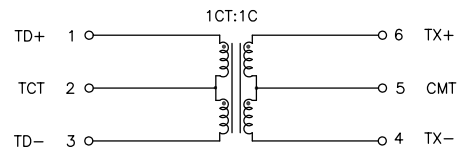


Soldering and Mounting

C.J-STD-075:R7,245°C Maximum Through Reflow Solder



COMPONENTS PER REEL: 400 pcs

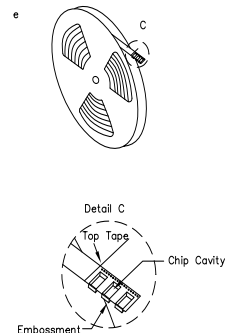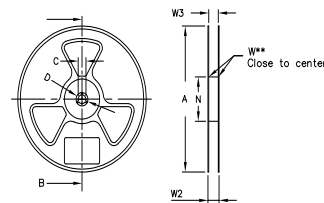

		A	B	C	D	N	W1	W2	W3	W3
Tolerance			min.	±0.8	min.	min.	+2.0	max.	min.	max.
Tape width	mm	330.00	1.50	13.00	20.20	100.00	16.4	18.4	16.4	18.3