

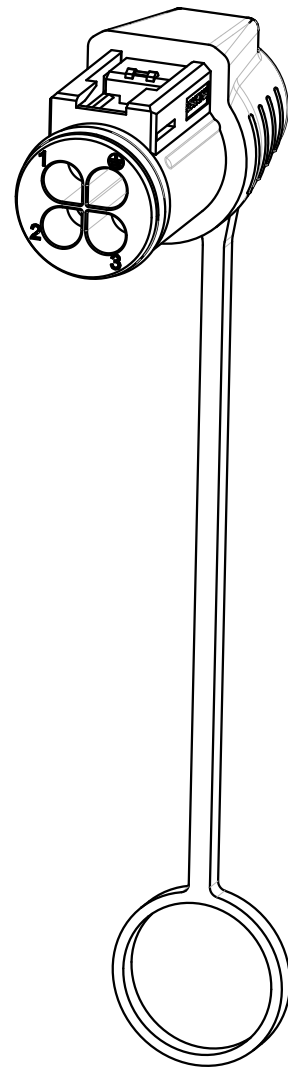



a : 7 : RL

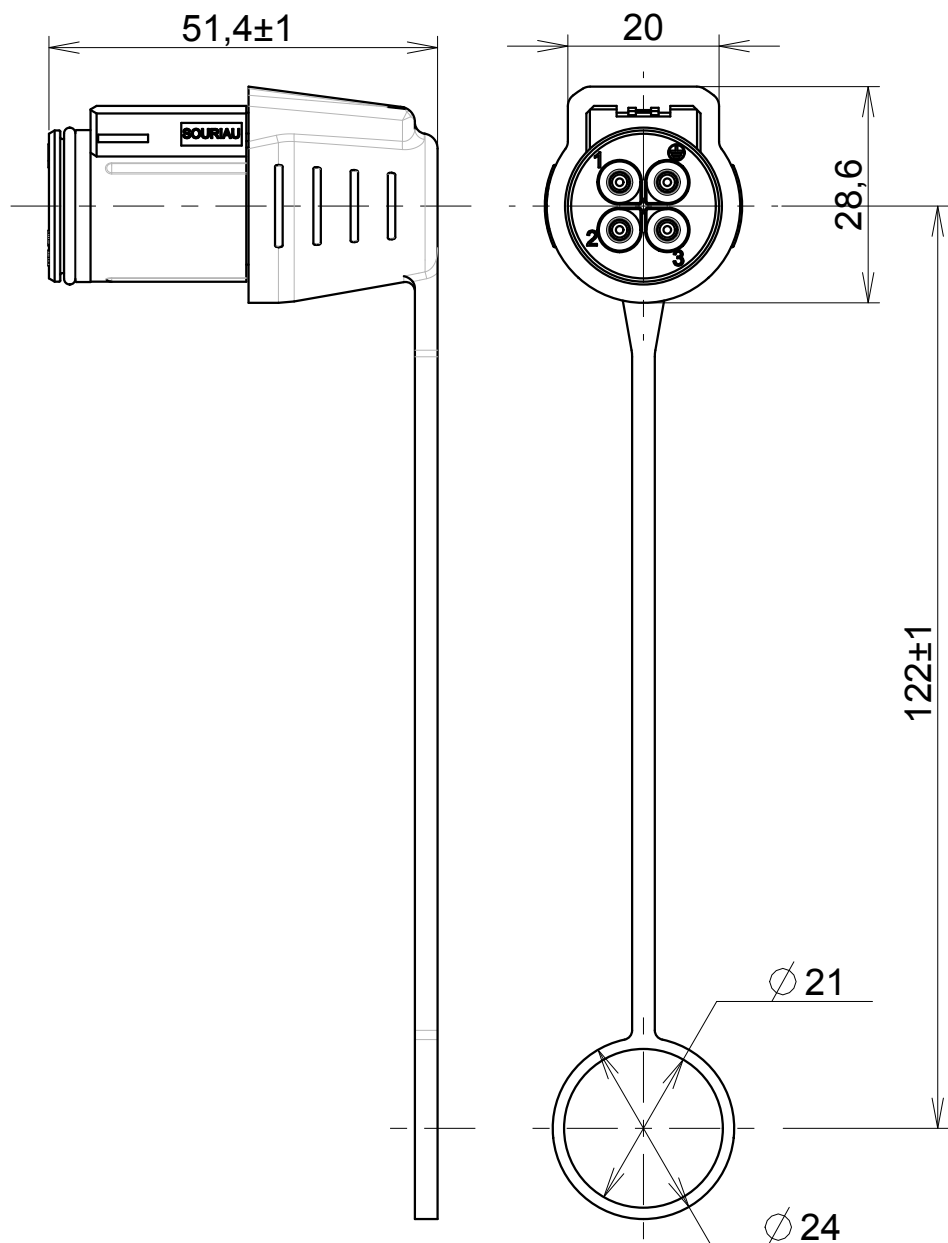


FOR MALE RECEPTACLE
P/N : UTL103G1PDCG68

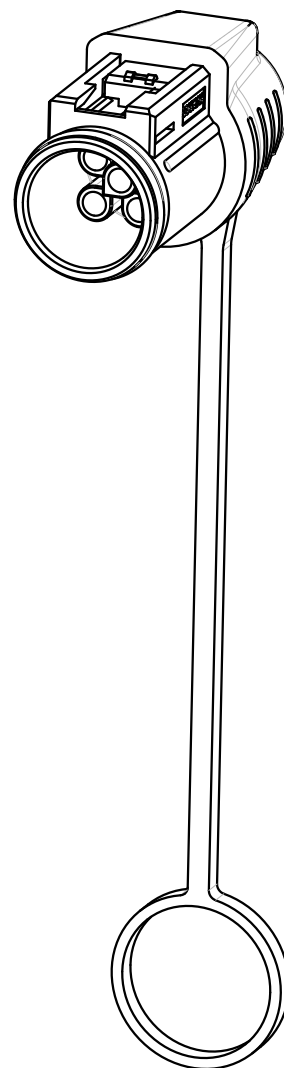

FOR FEMALE RECEPTACLE
P/N : UTL103G1SDCG68

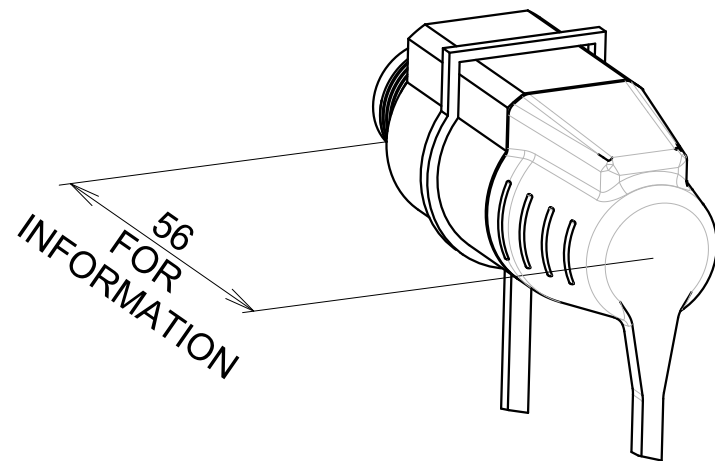

VIEW IN MATED CONDITIONS
WITH TYPE 1/ TYPE 7 RECEPTACLE

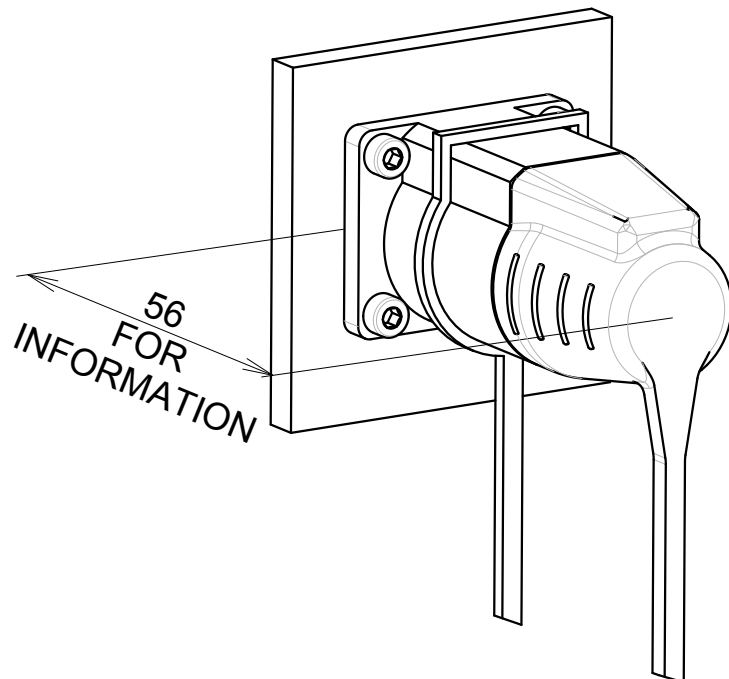

VIEW IN MATED CONDITIONS
WITH TYPE 0 RECEPTACLE

MATERIAL :

CONNECTOR SHELL : POLYAMID GLASS REINFORCED, BLACK COLOR
REAR LINK : EPDM
O'RING : LUBRICATED SILICONE
SEALS : SILICONE

PERFORMANCE CHARACTERISTICS :

MECHANICAL

TEMPERATURE CLASS

DURABILITY

SEALING IN MATED CONDITIONS

CORROSION SALT SPRAY

ROHS COMPLIANT

UNIT IN MM

IEC61984/UL1977

IEC61984

IEC60529

DIN40050


-40°C TO 105°C

500 MATE / UNMATE CYCLES

IP68 1BAR DURING 1WEEK

IP69K

MIN 1000H

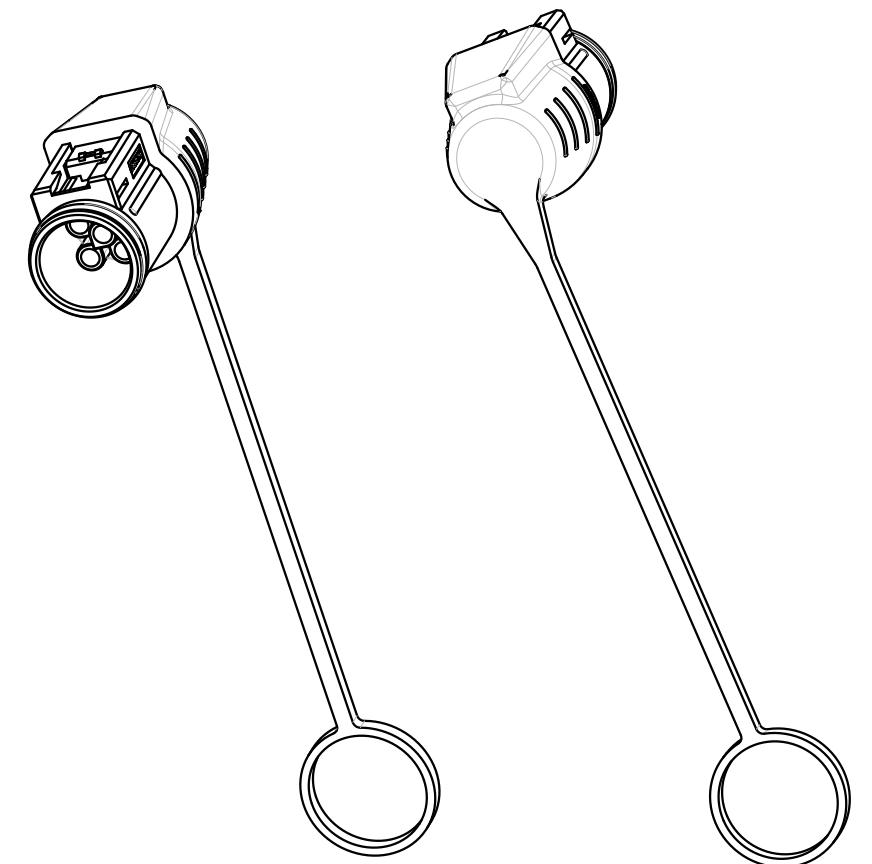

P/N : SEE VIEW

a	28/01/2013	First issue	
ISS	DATE	Latest modification - by:	MOD N°
Designed by:	R. M.	Date: 28/01/2013	CUSTOMER DRAWING
TITLE	IP68 LEVEL CAP FOR UTL RECEPTACLE UTL CONNECTOR		
Scale	1/1	General linear Tolerances: ± 0.3	NPRDS / PROJECT UTL
SOURIAU		WWW.SOURIAU.COM	This document is the property of SOURIAU It must not be reproduced or communicated without permission
FORMAT	A2	SOURIAU DRG N° UTL1-0044A-C01	SHEET 1/1

NOT EXPORT CONTROLLED