
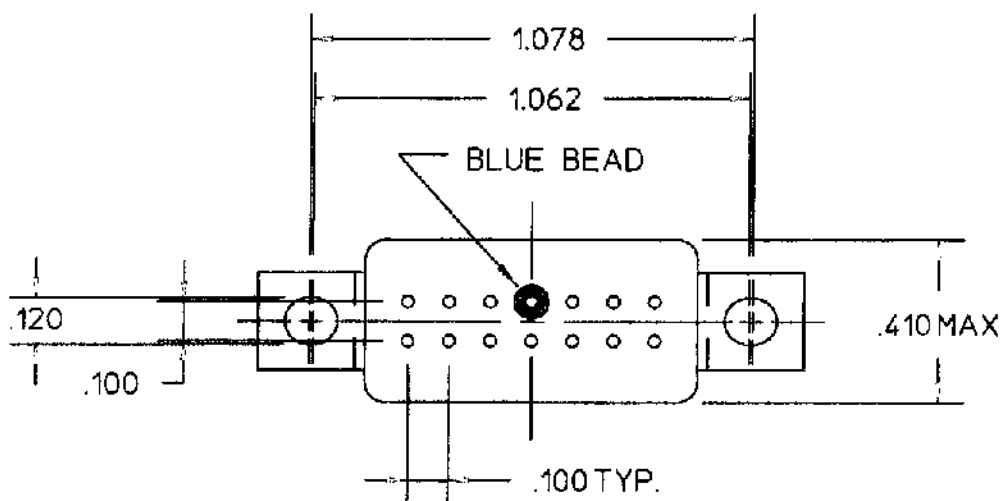


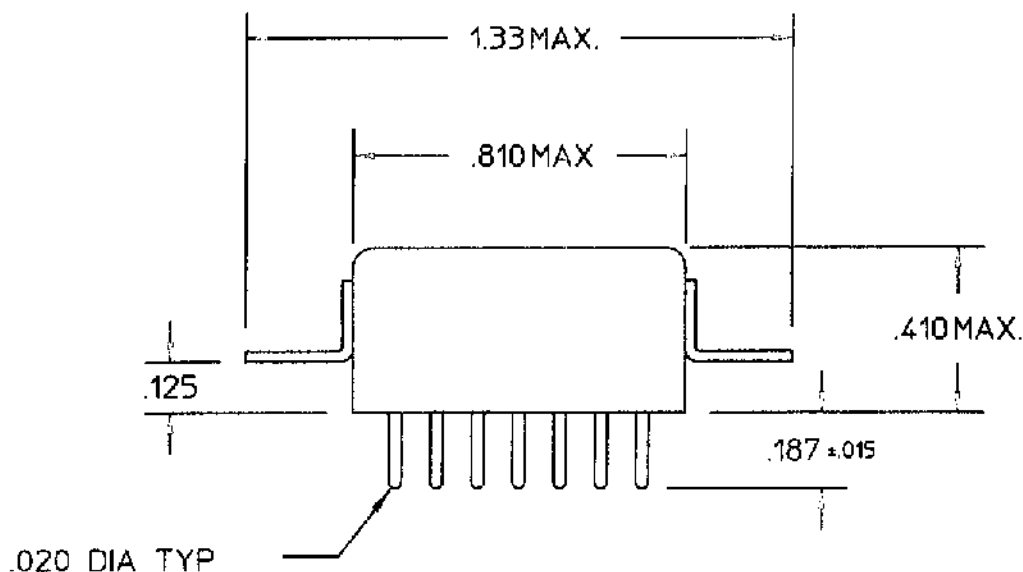

REV. 3
DCO 63333

COIL: @ 25°C
RESISTANCE _____ 390 OHMS ±10%
NOMINAL VOLTAGE _____ 26.5 VDC
MUST OPERATE _____ 14.0 VDC @ 25°C

MUST RELEASE _____ 1.4 VDC @ 25°C

ENVIRONMENT:


VIBRATION _____ 10 _____ CPS TO _____ 2000 _____ CPS @ _____ 15 _____ g's
SHOCK _____ 100 _____ g's _____ 6 _____ MS. DURATION
TEMPERATURE _____ -65 _____ °C TO _____ +125 _____ °C

NOTES: _____ TERMINALS ARE GOLD PLATED

OPERATE & RELEASE 5 MS MAX.

BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

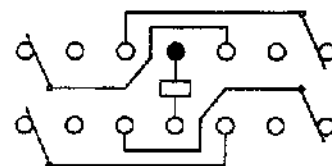

TERMINAL VIEW

CONTACT RATING: _____ LOW LEVEL TO
_____ 2 AMP 28 VDC RESISTIVE

DR. R.B. 11/29/90 CK. TLG 10-24-00

CNI Technologies
advanced control electronic solutions

CUST. _____ CII STD

CUST. NO. _____ REV. _____

'SRBW' RELAY

SRBW-4C-24G