


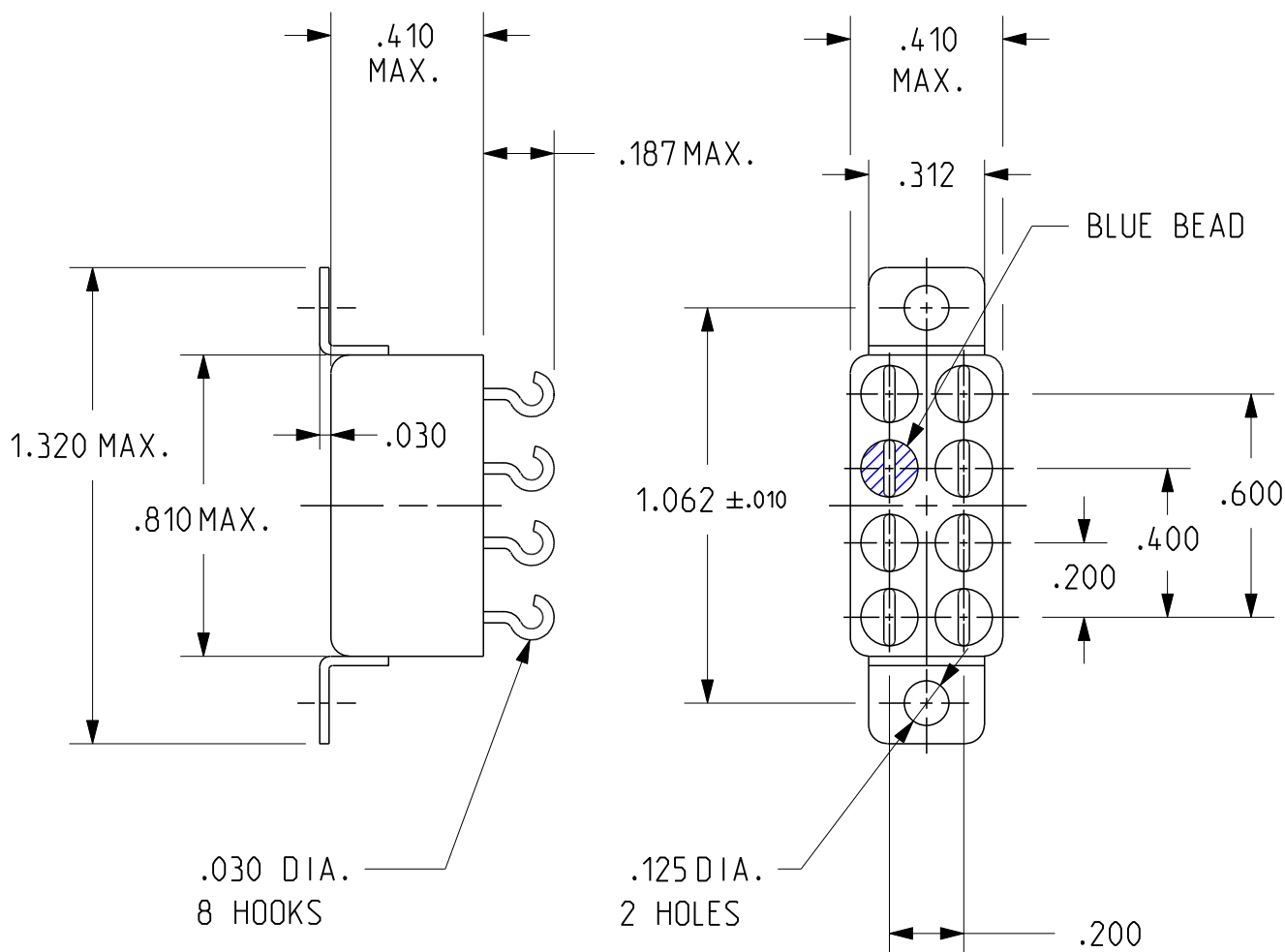


REV. B
DCO 17799

COIL: @ 25°C	
RESISTANCE	900 OHMS ±10%
NOMINAL VOLTAGE	26.0 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.3 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 30 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

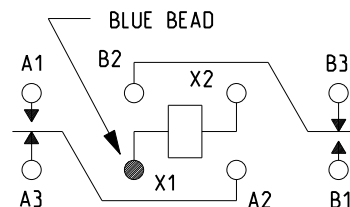

TERMINAL VIEW

CONTACT RATING: LOW LEVEL
TO 2 AMPS 28 VDC RESISTIVE
100.000 OPERATIONS

DR. R.B. 10/14/98 CK. J.M.B. 1/12/10

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. BABCOCK
CUST. NO. BR16-900B11-26V REV.

TE NUMBER
4-1617028-9

CII PART NUMBER
HFW 11134S01