

S-6
CANDELABRA
SCREW BASE

See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.

75W., 125V.



Large Incandescent Indicators


FOR MOUNTING IN 1" CLEARANCE HOLE
FOR 6 TO 250V OPERATION

These series indicator lights meet or exceed requirements of MIL-L-3661.

MATERIALS AND FINISHES

- **Mounting Bushing:** Standard—brass, white nickel finish. Optional—black nickel finish.
- **Lens Holder and Knurled Flange Ring:** Brass, polished chrome finish. Optional—black nickel or satin chrome finish.
- **Mounting Nut:** Brass, white nickel finish.
- **Internal-tooth Lockwasher:** Phosphor bronze, white nickel finish.
- **Terminals:** Solder — brass, hot tinned. Screw—brass, white nickel finish. Quick Connect—brass, tinned. Mate with standard female receptacles.

These assemblies are shown with screw-on or friction-fit lens caps, Bayonet lock lens caps are also available. Information will be furnished upon request.

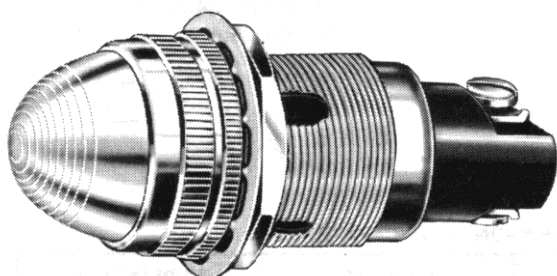

80-0901-0511-301
Torpedo lens

80 SERIES

How to designate the three digit part number suffix (-XXX)

Finish	Resistor	Hardware
2 — black nickel		1 — brass
3 — polished chrome	0 — none	3 — water-tight on the face of the panel, (screw-on caps only).
4 — satin chrome		

WITH SCREW-ON LENS CAPS

solder terminal	screw terminal (side pos.)	screw terminal (protruding pos.)
80-4001-05-301	80-0901-05-301	80-3101-05-301

BASE PART NUMBERS

CAP PART NUMBERS

COMPLETE ASSEMBLY PART NUMBERS

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS		
TORPEDO 80-0511-300 back frosted 80-0531-300 unfrosted	80-4001-0511-301	80-0901-0511-301	80-3101-0511-301
DOME 80-1211-300 back frosted 80-1231-300 unfrosted	80-4001-1211-301	80-0901-1211-301	80-3101-1211-301
TORPEDO FACETED 80-1331-300 unfrosted	80-4001-1331-301	80-0901-1331-301	80-3101-1331-301

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.

Order complete with lamp to be assured of receiving the
indicator light and correct lamp together for immediate use.