


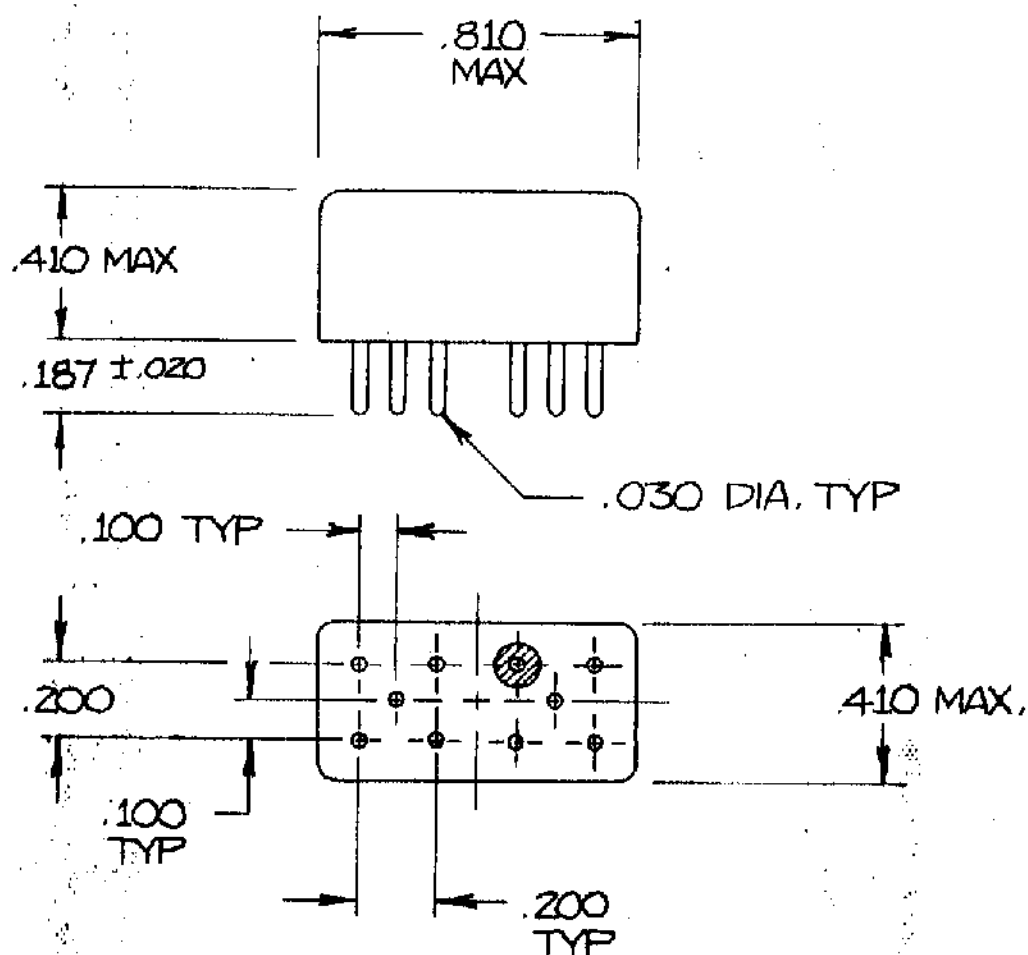

COIL: 26.5 VDC NOMINAL

WINDING #1

WINDING #2

1000 OHMS ± 10%

1000 OHMS ± 10%

8-13 VDC MUST OPERATE

8-13 VDC MUST OPERATE

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's


SHOCK 50 g's 11 MS.DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

CONTACTS WILL SWITCH FROM THE INDICATED POSITION WHEN EITHER COIL IS ENERGIZED WITH POLARITY SHOWN.

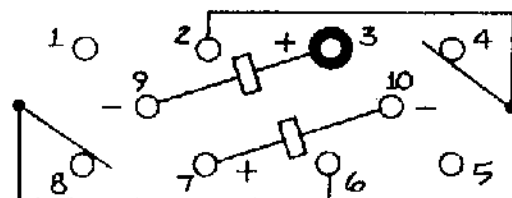

CONTACT RATING:
2 AMP / 28 VDC RESISTIVE

DR. R.B. 4-5-90 CK. JAW 4-5-90



Communications
Instruments, Inc.

CUST. CII STD

CUST. NO. _____

TYPE "LS" RELAY

LSAW-ZC-24B