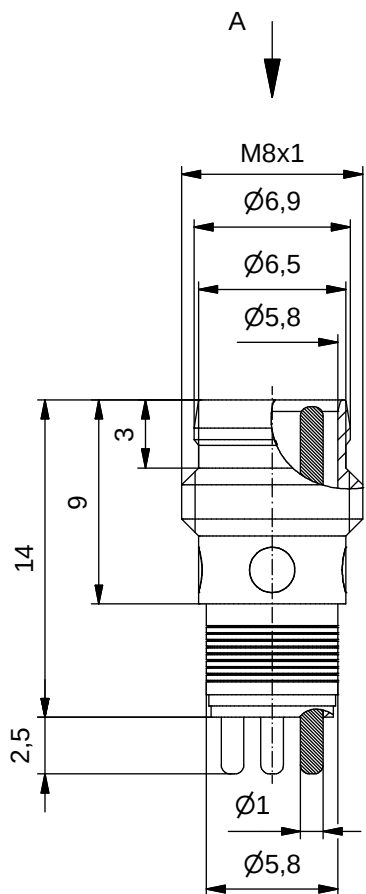


Technical specification:

Rated voltage: IEC 61076-2-104	3pos 4pos 60 V 30 V
Current rating: IEC 61076-2-104	3 A bei 40°C
Insulation resistance: IEC 60512	>=100 MΩ
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, in mated condition
Temperature range: IEC 60664-1	-30°C ... +85°C
Mating cycles: IEC 60512-9a	>=100

Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	PA , UL 94
Socket housing:	CuZn, Nickel plated

Part no:	Description:	Pos
42-01016	SAL - 8 - ESVM3 - P	3
42-01017	SAL - 8 - ESVM4 - P	4

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: a 02.03.11 fro Ä3914 Data sheet revised
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH

	date	name
drawn	15.10.08	Fromm
appd.	15.10.08	Mankopf

CONEC®

title: Male socket M8x1 with dip solder
dwg no: 42K1A116
part no: