



INTERCONNECTS

SERIES 712 • 2,54 GRID CARRIER WITH SOLDER TAIL • SINGLE AND DOUBLE ROW STRIPS

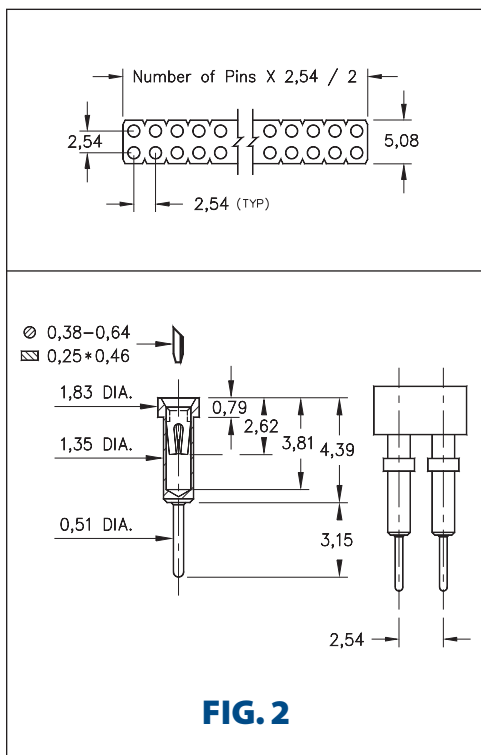

- Standard solder tail receptacles can be mounted as a low profile receptacle or by the solder tail for use in smaller diameter holes
- Series 712 use MM #0255 pins. See page 165 for details
- Hi-Rel, 4-finger BeCu #30 contact is rated at 3 amps. See page 253 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

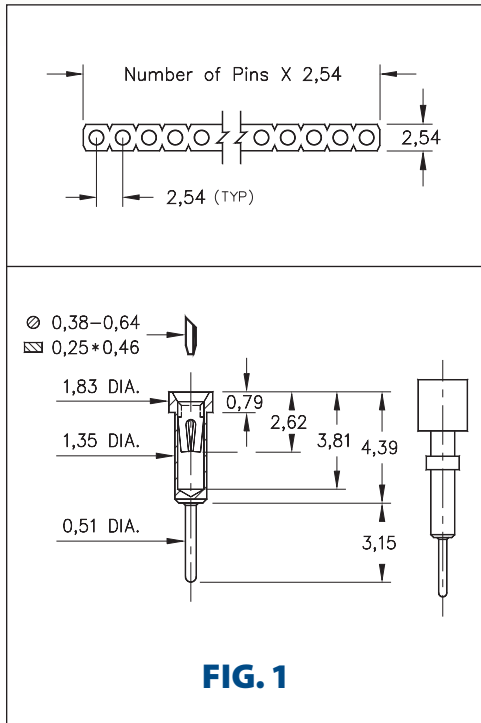

ORDERING INFORMATION

FIG. 1	Single Row (0,71 or 1,4 min. mounting holes)	
	712-XX-1	-41-001000
	Specify number of pins	01-64
FIG. 2	Double Row (0,71 or 1,4 min. mounting holes)	
	712-XX-2	-41-001000
	Specify number of pins	04-64



XX=Plating Code
See Below

For
Electrical, Mechanical
& Environmental Data,
See page 264

SPECIFY PLATING CODE XX=	11	13	91	93	41	43	
Sleeve (Pin)	0,25µm Au	0,25µm Au	5,08µm Sn/Pb	5,08µm Sn/Pb	5,08µm Sn	5,08µm Sn	
Contact (Clip)	0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au	

