

INTERCONNECTS

SERIES 714...01X • 2,54 GRID ULTRA LOW PROFILE CARRIERS • SINGLE AND DOUBLE ROW STRIPS

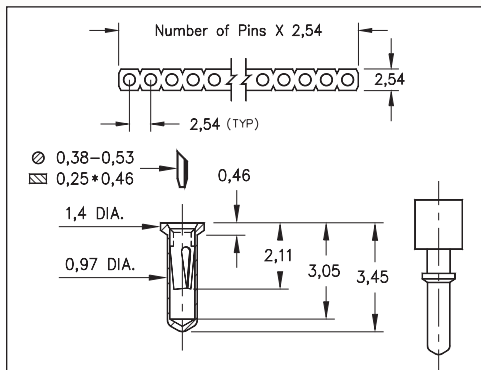


FIG. 1

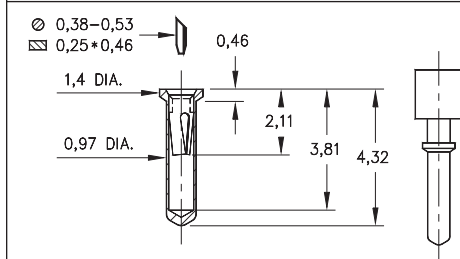


FIG. 2

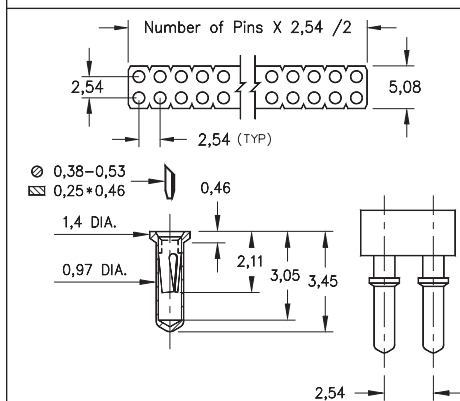


FIG. 3


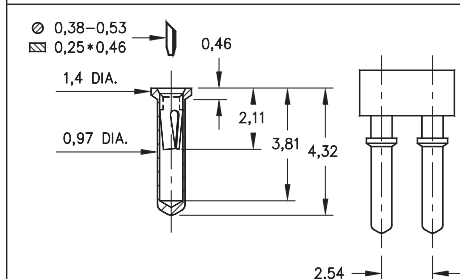


FIG. 4

- Ultra low profile receptacles sit 0,46 above the board
- Series 714 use MM #0552-1 and MM #0552-2 pin receptacles. See page 158 for details
- Hi-Rel, 3-finger BeCu #11 contact is rated at 3 amps. See page 251 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

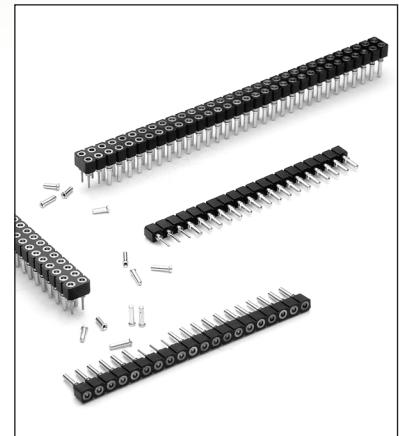

ORDERING INFORMATION

FIG. 1	Single Row (0,99 min. mounting hole)			
	714-XX-1-31-012000	Specify number of pins 01-64		
FIG. 2	Single Row (0,99 min. mounting hole)			
	714-XX-1-31-018000	Specify number of pins 01-64		
FIG. 3	Double Row (0,99 min. mounting hole)			
	714-XX-2-31-012000	Specify number of pins 04-64		
FIG. 4	Double Row (0,99 min. mounting hole)			
	714-XX-2-31-018000	Specify number of pins 04-64		
RoHS-2 2011/65/EU XX=Plating Code See Below For Electrical, Mechanical & Enviromental Data, See page 264				
SPECIFY PLATING CODE XX=				
Sleeve (Pin)	91	93	41	43
Contact (Clip)	0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au