

Incandescent Indicators



T-1 3/4
MIDGET
FLANGE BASE

See lamp ratings
on page J.

TWO TERMINALS—FULLY INSULATED

FOR MOUNTING IN 15/32" CLEARANCE HOLE

MEET OR EXCEED ENVIRONMENTAL AND OPERATIONAL REQUIREMENTS
OF MIL-L-6723 AND MIL-L-3661B

Feature

- Anti-rotation (locked) construction: Provides for secure locking of the socket terminal assembly in the mounting bushing and of the center terminal to the insulating disc. The notched mounting bushing receives the matched insulating disc to prevent the rotation of the mounting bushing.


How to designate the Three Digit Part Number Suffix (—XXX)

Finish	Resistor	Hardware
5 — black anodize	0 — none	2 — steel
6 — clear anodize		

Example: 162-8430-0971-602 (clear anodize finish, no resistor, steel hardware).


MATERIALS AND FINISHES

- **Mounting Bushing:** Aluminum, black anodize finish. Optional— clear anodize finish.
- **Internal-tooth Lockwasher and Mounting Nut:** Steel, cadmium plated with yellow iridescent chromate finish.
- **Terminals:** Brass, hot tinned with elongated slot.

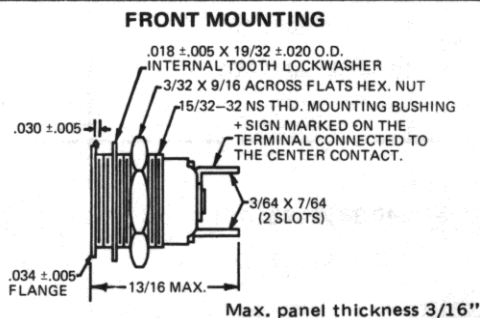


162 SERIES
178 SERIES

BASE PART NUMBERS

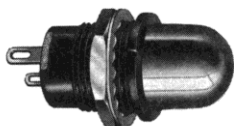

162-8430-0971-502

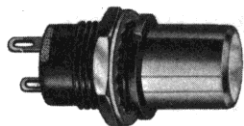


162-8430-1471-502



178-8430-0371-502



178-8430-0111-502

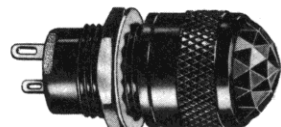

178-8430-2131-502

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS
STOVEPIPE 162-0971 translucent	162-8430-0971-502
CYLINDRICAL 162-1431 transparent 162-1471 translucent	162-8430-1431-502 162-8430-1471-502
FLAT 178-0331-500 transparent 178-0371-500* translucent	178-8430-0331-502 178-8430-0371-502
CONVEX 178-0131-500 unfrosted 178-0111-500 back frosted	178-8430-0131-502 178-8430-0111-502
FACETED 178-2131-500 unfrosted	178-8430-2131-502

*Specify translucent colors as follows: Red -0371;
Green -0372; Yellow (amber) -0373; Blue -0374;
White -0375; Light yellow -0376.

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.