


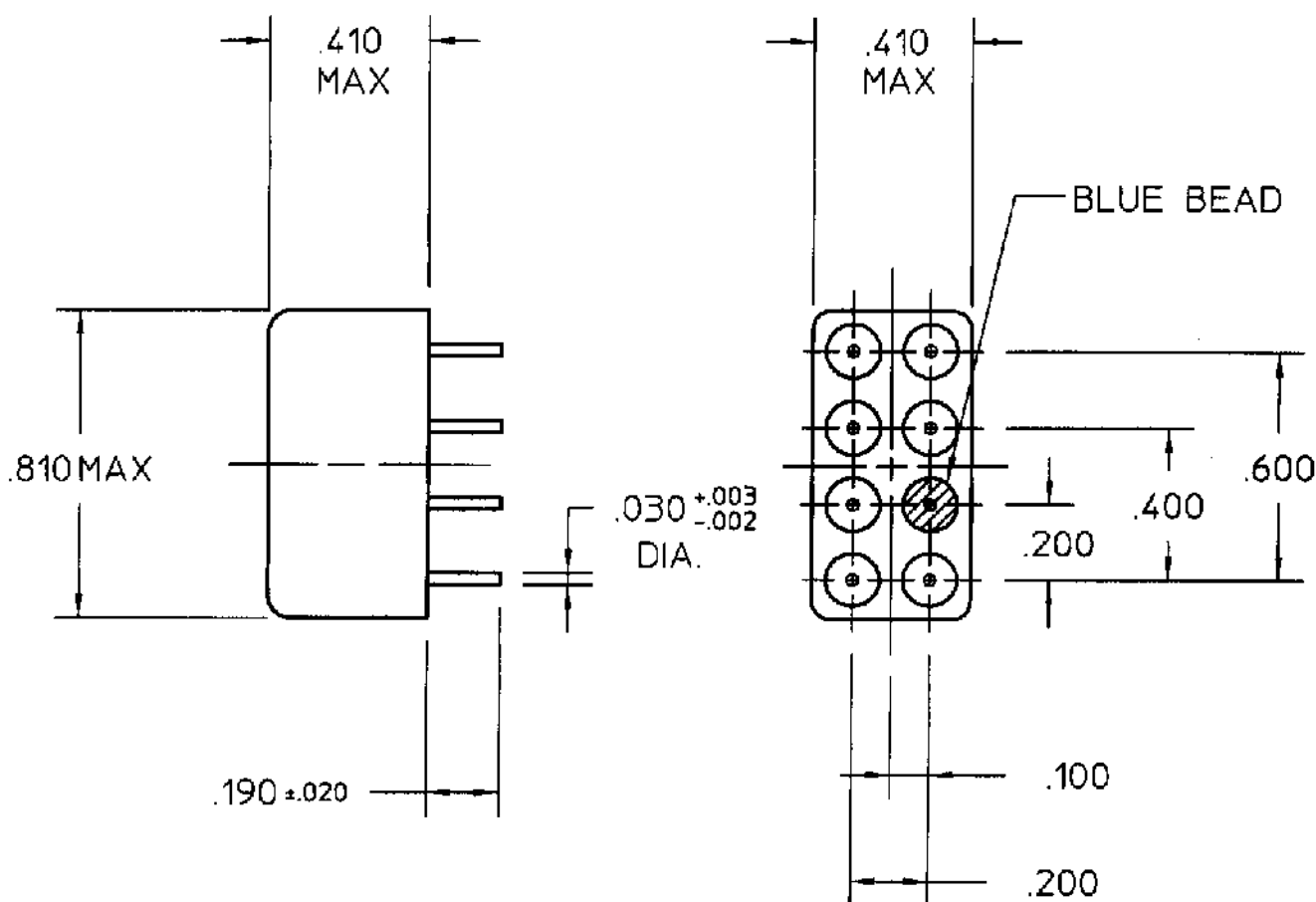

REV. 0

DCO 16653


COIL: @ 25°C
 RESISTANCE 180 OHMS ±10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 7.7 VDC
 MUST RELEASE 5.4 MAX., 0.85 MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 10 g's
 SHOCK 50 g's 6 MS. DURATION
 TEMPERATURE -14 °C TO +125 °C

NOTES: OPERATE 6 MS MAX
 RELEASE 4 MS MAX
 CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

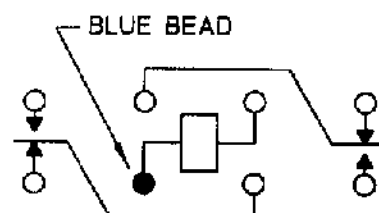

TERMINAL VIEW

CONTACT RATING: 50 µA @ 50 mV PEAK
 AC OR DC 100,000,000 OPERATIONS
 2 AMPS 28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 11/30/00 CK. TLG 11-30-00

CII Technologies™
 advanced control electronic solutions

CUST. C. I. I. STD.

CUST. NO. REV.

"3SCV" RELAY

3SCV5004D1