



Mallory Sonalert Products, Inc.

Part #:

SBM616JUR

Sales Outline Drawing

Revision:


A

Specifications:

Sound Level Category	Medium
Mode of Operation	Continuous or Slow Pulse @ 0.5 - 2.5 PPS
Voltage Rating	6 to 16 VDC
Frequency	2900 $\pm$ 500 Hz
Loudness @ Min Vdc	68 dB(A) @ 2 Feet and 6 Vdc
Loudness @ Max Vdc	78 dB(A) @ 2 Feet and 16 Vdc
Current Draw	3-12mA
Duty Cycle (%)	50
Mounting	Printed Circuit Board (See Note B)
Housing Material	6/6 Nylon, Color: Black
Storage Temperature	-40° to +85° C
Operating Temperature	-30° to +65° C
Weight (Typical)	0.6 oz (17g)
Options	Please contact factory.

Dimensions: Inches (mm)

ROHS Compliant

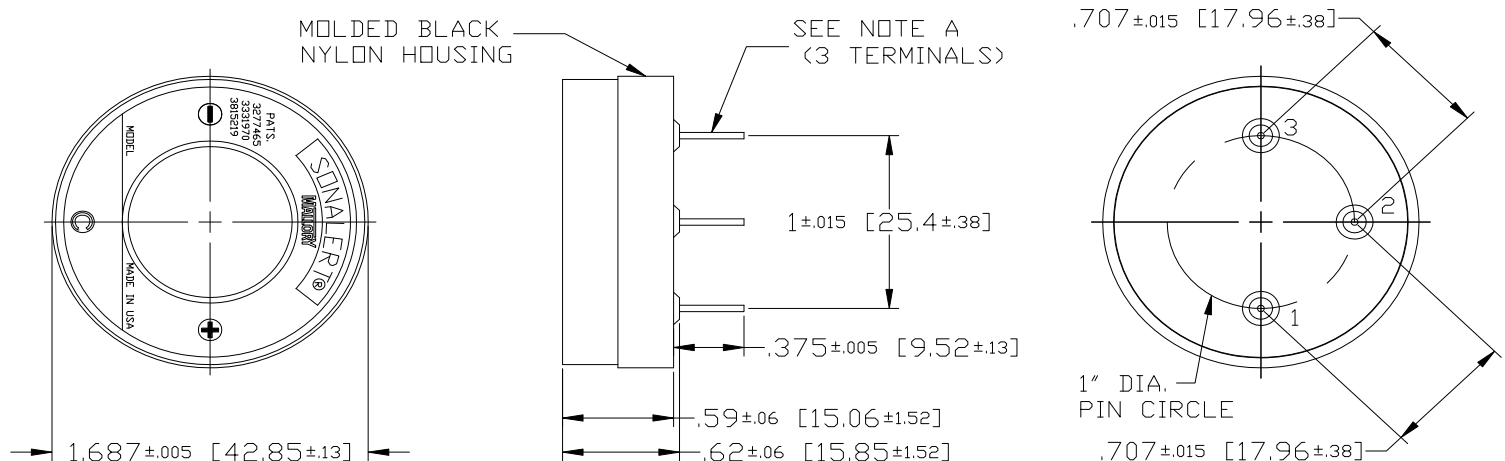

NOTE A:


TERMINALS - .031" DIA. SOLDER COATED
COPPER-CLAD STEEL.

TERMINAL 1 IS POSITIVE (CONTINUOUS),
TERMINAL 3 IS NEGATIVE,
TERMINAL 2 IS POSITIVE (PULSE).

NOTE B:

MOUNTING - INSERT INTO PRINTED CIRCUIT
BOARD AND HAND OR MACHINE SOLDER.

WIRING DIAGRAM

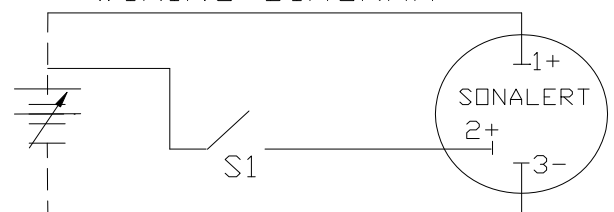

IF S1 IS OPEN, UNIT IS CONTINUOUS
IF S1 IS CLOSED, UNIT IS PULSATING