




TOP VIEW

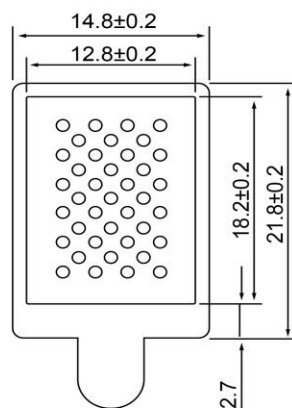

SIDE VIEW

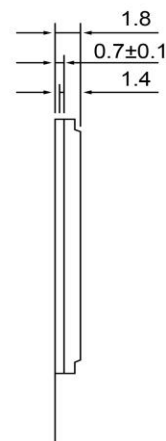

BOTTOM VIEW

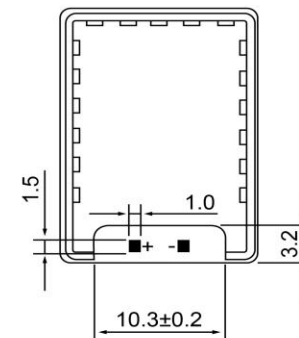

Specifications

Description	Value	Unit
Shape	Rectangle	
Resonant Frequency	1,000	(Hz)
Frequency Range	1,000 ~ 20,000	(Hz)
SPL @ 10cm	86	(dBA)
Capacitance	600	(nF)
Diaphragm Material	Piezo	
Rated Voltage	7	(Vrms)
Max Input Voltage	9	(Vrms)
Mount Type	Flush mount	
Operating Temperature	-20 ~ +70	°C
Storage Temperature	-30 ~ +85	°C
Weight	1	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			3/24/2015	J.S.

Piezo Speaker

SZ211006-1

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.