


AUTO LINK PAL FUSES - 294C

RoHS

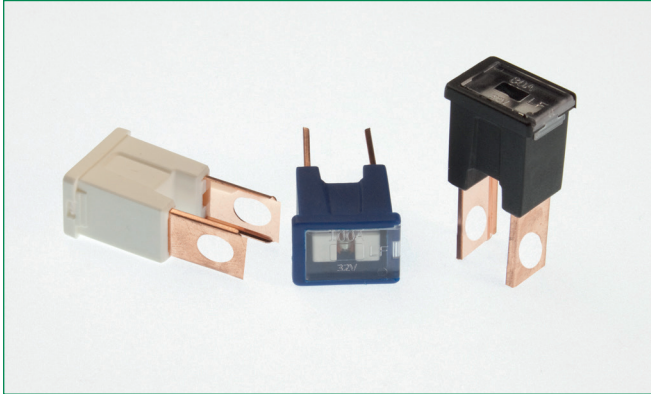

Description

PAL fuses are commonly found on many Japanese and domestic built vehicles.

Specifications

Voltage Rating: 32 VDC
Current Cycling: 24°C
The fuses satisfy the performance requirements after 50% of the rated current is applied for 10,000 cycles. Each cycle consists of an interrupted current with the pattern of 5 minutes ON and 10 minutes OFF.
Operating Temperature Range: -40°C to +125°C

Complies with JASO 0612

Ordering Information

Part Number	Package Size
0294xxx.MXJ-C	1000

Time-Current Characteristics

% of Rating	Opening Time Min / Max (s)
110	14,400 s
200	5 s / 100 s
350	0.2s / 7 s
600	0.040 s / 1 s

Ratings

Part Number	Current Rating (A)	Body Color
0294020._	20	LIGHT BLUE
0294030._	30	PINK
0294040._	40	GREEN
0294050._	50	RED
0294060._	60	YELLOW
0294070._	70	BROWN
0294080._	80	BLACK
0294100._	100	BLUE
0294120._	120	WHITE

Dimensions

Dimensions in mm

