


PIN RECEPTACLES

FOR 0,51 - 0,81 DIAMETER PINS

0338

0338-0-15-XX-15-XX-10-0


Solder mount in 1,45 min. mounting hole
Also available on 16mm wide carrier tape:
1,700 parts per 330mm reel
Order as: 0338-0-57-XX-15-XX-10-0

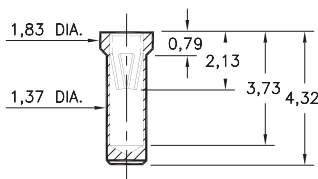

0378

0378-0-15-XX-15-XX-10-0


Solder mount in 2,08 min. mounting hole

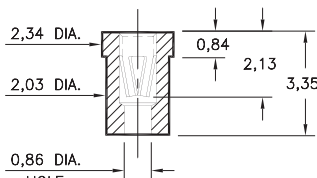

6002

6002-0-19-XX-15-XX-10-0


Solder mount in 1,5 min. mounting hole
Wire Termination. Accepts wire sizes
26 AWG Max. / 30 AWG Min.

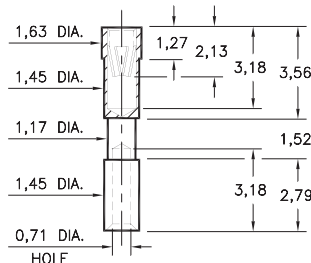

7009

7009-0-19-XX-15-XX-10-0


Press-fit in 1,6 min. mounting hole
Wire Termination. Accepts wire sizes
22 AWG Max. / 26 AWG Min.

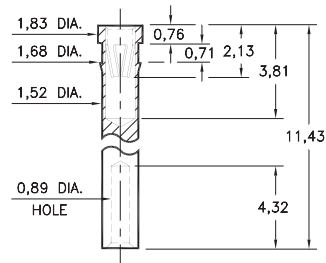

0339

0339-0-15-XX-15-XX-10-0


Solder mount in 1,45 min. mounting hole
Also available on 24mm wide carrier tape:
1,540 parts per 330mm reel
Order as: 0339-0-57-XX-15-XX-10-0

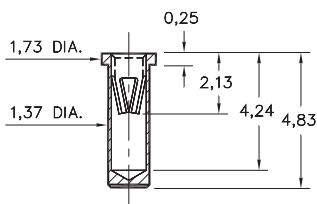

5200

5200-0-19-XX-15-27-10-0

Surface mount on a 2,62 dia. P.C.B. pad

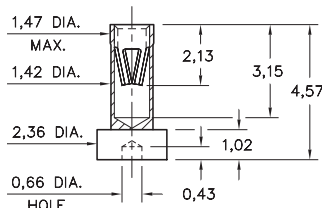

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: $\pm 0,13$

Diameters: $\pm 0,051$

Angles: $\pm 2^\circ$



ORDER CODE: XXXX - X - XX - XX - 15 - XX - 10 - 0

BASIC PART #

SPECIFY SHELL FINISH:

01 5,08 μ m TIN/LEAD OVER NICKEL

◆ **80** 5,08 μ m TIN OVER NICKEL (RoHS)

◆ **15** 0,25 μ m GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

01 5,08 μ m TIN/LEAD OVER NICKEL

◆ **80** 5,08 μ m TIN OVER NICKEL (RoHS)

◆ **27** 0,76 μ m GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#15 CONTACT (DATA ON PAGE 254)

(For alternate contact choices, see group K on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com